

TCF

**FEATURES**

- ※Miniature 2.9x4.5mm
- ※Side push mid-mount type
- ※200,000 operating life cycles

**APPLICATION**

- ※Smart phone
- ※Portable personal audio
- ※Digital camera

**SPECIFICATION**

Contact Rating	10μA, 2V DC to 20mA, 15V DC
Contact Resistance	1000mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160±50gf/240±70gf
Travel	0.15mm
Operating Life	200,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

**HOW TO ORDER**


TCF □ QR

Package:  
Tape & Reel

Halogen Free

Operating Force:  
2=160gf  
3=240gf

**CIRCUIT**

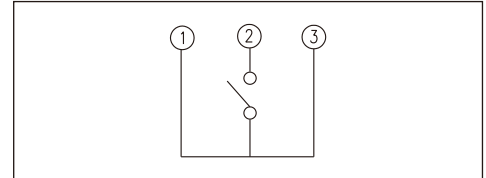

**PACKAGE**

<Tape & Reel>  
2400 pcs

TACT SWITCH

**TCF**

