


Model(型號): DS-08-R-T 2.54mm 8POS DIP


KE Switches

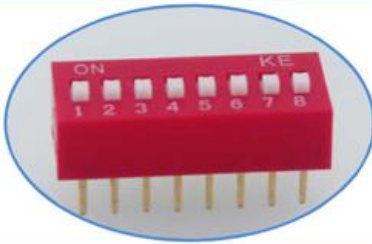

※ Features:

- ▶ Lowest contact resistance less than 50mΩ.
- ▶ Gold-plated contact provides high reliability.
- ▶ All materials are UL 94V0 grade, high temperature resistant plastic.
- ▶ All DIP switches Packaging are IC TUBES and the switches are OFF state.
- ▶ Shell colour: Red or Blue or Black.

※ Dimensions(規格圖): DS Series

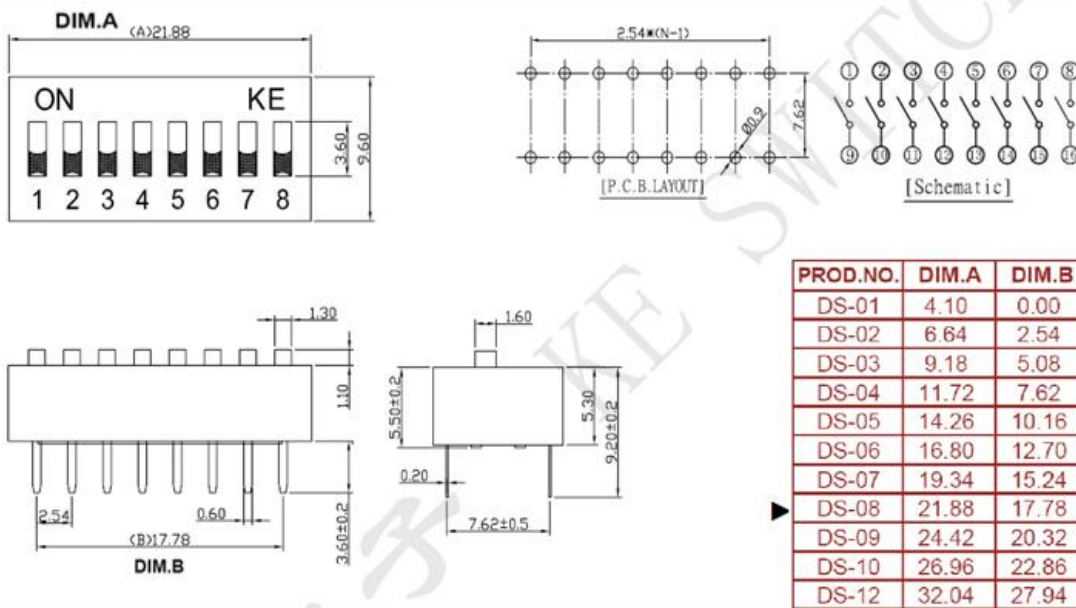

※ Specifications(規格)

● Electrical Characteristics [電氣性能]

Positions [位數]	▶ <input type="checkbox"/> 1 <input type="checkbox"/> 2 <input type="checkbox"/> 3 <input type="checkbox"/> 4 <input type="checkbox"/> 5 <input type="checkbox"/> 6 <input type="checkbox"/> 7 <input checked="" type="checkbox"/> 8 <input type="checkbox"/> 9 <input type="checkbox"/> 10 <input type="checkbox"/> 12
Contact Rating [触点容量]	▶ Switching: DC24V 25mA Non-Switching: DC50V 100mA
Contact resistance [接觸阻抗]	▶ 50mΩ Max at initial ; 100mΩ Max after life test
Insulation resistance [絕緣阻抗]	▶ 1000MΩ Min at DC500V
Dielectric strength [耐電壓]	▶ 1 minute at AC 500VAC
Wave soldering [波峰焊]	▶ 255 ± 5°C for 3---5 Seconds

● Mechanical Characteristics [機械性能]

Circuit [開關形式]	▶ SPST
Operation force [動作力]	▶ 1000gf Max
Operating Temperature Range [工作溫度範圍]	▶ -30°C~85°C
Storage Temperature Range [儲存溫度範圍]	▶ -40°C~85°C
Packing Specifications [包裝規格]	▶ 22 PCS / Tube, 1100 PCS / Box

● Endurance Characteristics [耐久性能]

Mechanical life [機械壽命]	▶ 3,000 Cycles Operations
--------------------------	---------------------------

Http://www.kswitch.com

Email:kswitch@126.com

TEL:(86)0769-82633166

FAX:(86)0769-82633255