


产品详细信息 introduce

线对板连接器 >> Du Pont2.0

产品订购

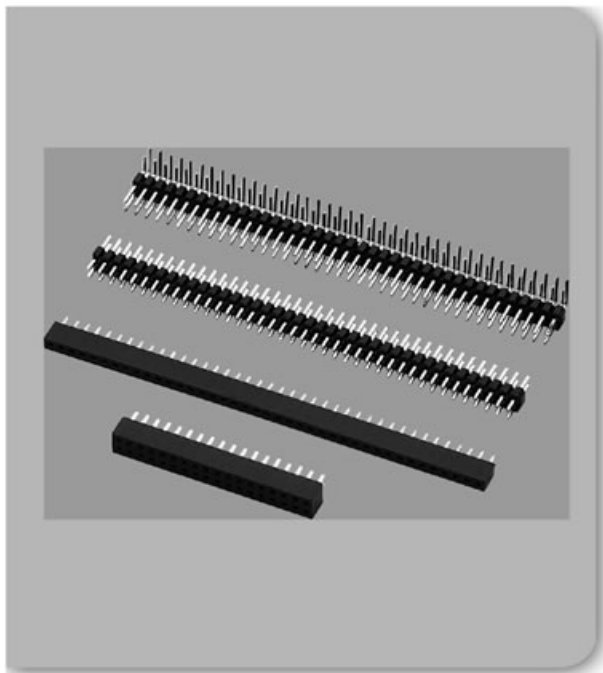


◆ SPECIFICATIONS

Unit:mm


- ◇ Poles: (YS)2~25x2, (AS, WAS)2~40x2
- ◇ Applicable wire: AWG#26-#30
- ◇ Voltage rating: 250V DC/AC
- ◇ Current rating: 1.0A
- ◇ Withstand voltage: 800V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.02Ω

UL:Recognized No.E309635  
RoHS-specification and Halogen-free products


Du Pont2.0-2xnA

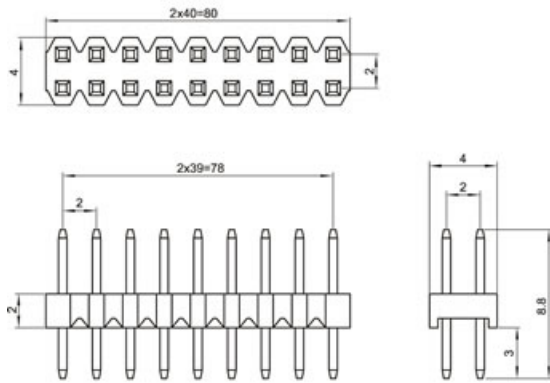

Du Pont2.0-2xnAW

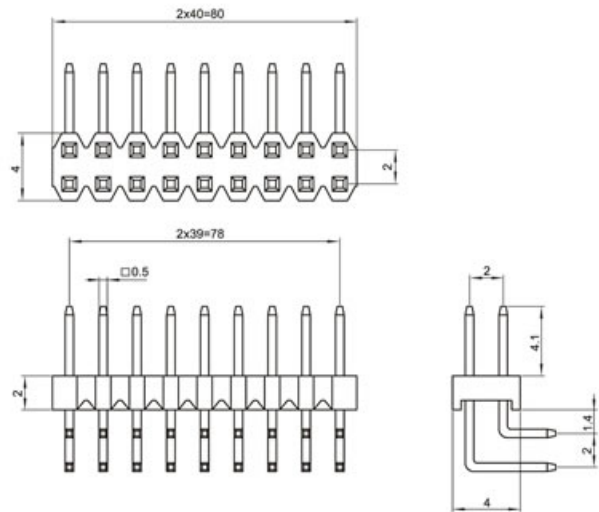


Du Pont2.0 排母

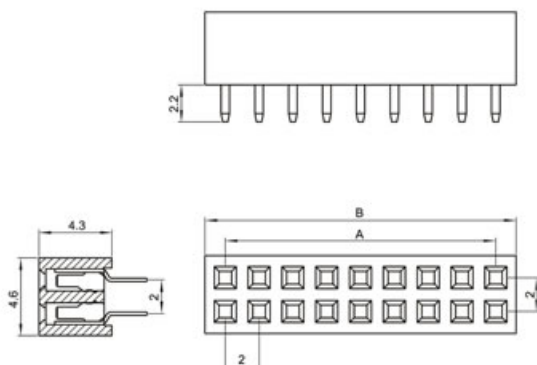


Du Pont2.0-2xnY


Unit:mm

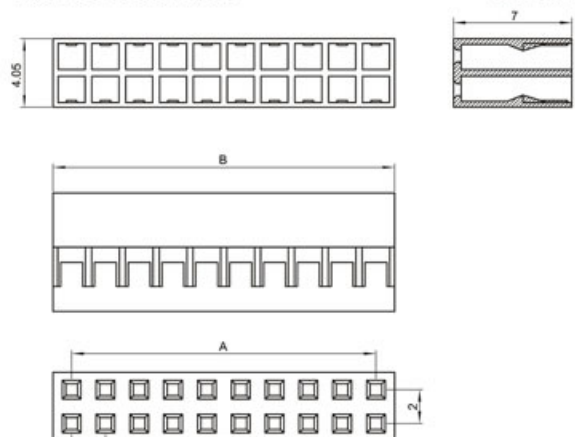

**Du Pont2.0-PT**

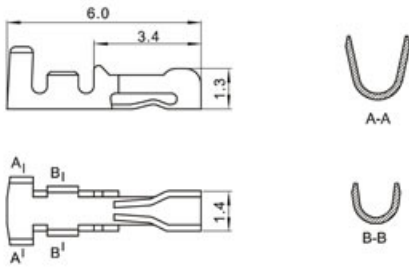


**Du Pont2.0-2xnYS**

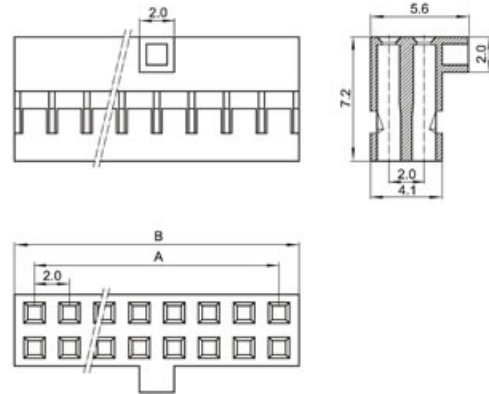

Poles	Type	Size(mm)	
		A	B
4	Du Pont-2x2A	2.0	4.0
6	Du Pont-2x3A	4.0	6.0
8	Du Pont-2x4A	6.0	8.0
10	Du Pont-2x5A	8.0	10.0
12	Du Pont-2x6A	10.0	12.0
14	Du Pont-2x7A	12.0	14.0
16	Du Pont-2x8A	14.0	16.0
18	Du Pont-2x9A	16.0	18.0

Poles	Type	Size(mm)	
		A	B
20	Du Pont-2x10A	18.0	20.0
22	Du Pont-2x11A	20.0	22.0
24	Du Pont-2x12A	22.0	24.0
26	Du Pont-2x13A	24.0	26.0
28	Du Pont-2x14A	26.0	28.0
30	Du Pont-2x15A	28.0	30.0
...	...	...	...
50	Du Pont-2x25A	48.0	50.0

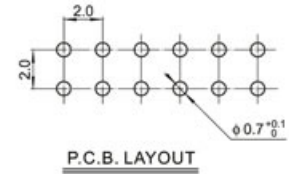

点击次数: 1244 发布时间: 2010-6-14 【打印】 【返回】

 [产品订购](#)