


产品详细信息 introduce

线对板连接器 >> Du Pont1.27

产品订购

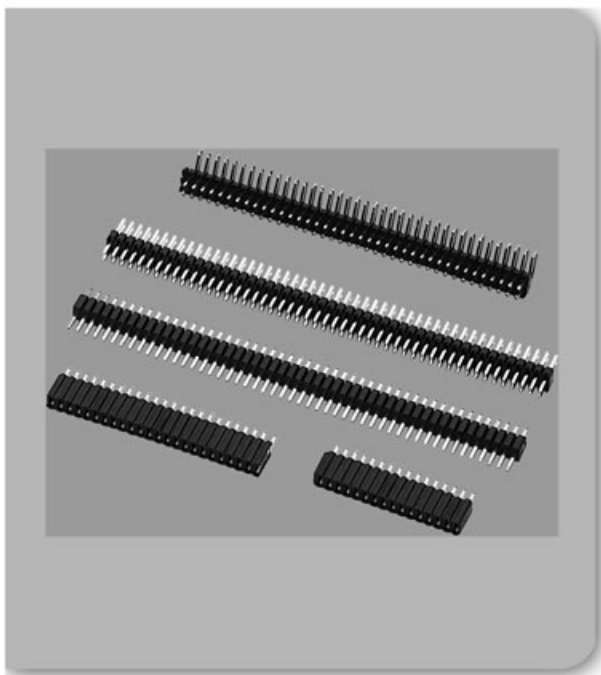




**SPECIFICATIONS**

  Unit:mm




- ◇ Poles: 2~40
- ◇ Applicable wire: AWG#26-#30
- ◇ Voltage rating: 250V DC/AC
- ◇ Current rating: 1.0A
- ◇ Withstand voltage: 800V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.01Ω
- ◇ Applicable PC board thickness: 0.6~1.2mm

UL:Recognized No.E309635  
 RoHS-specification and  
 Halogen-free products

**Du Pont1.27-1-nA**

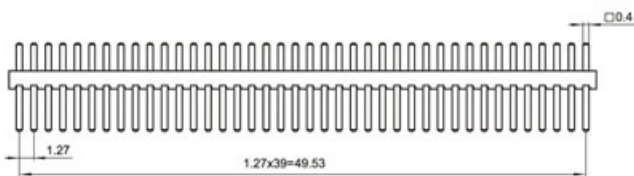




**Du Pont1.27-2-nA**

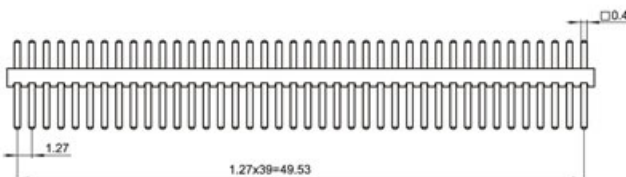  


**Du Pont1.27-2-nAW**

 Unit:mm

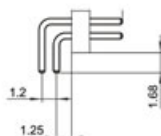

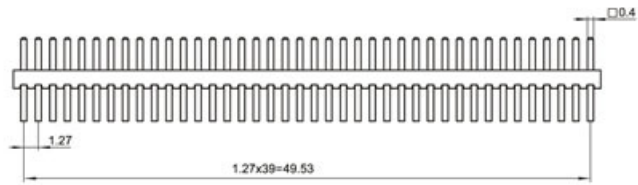

**Du Pont1.27 排母**

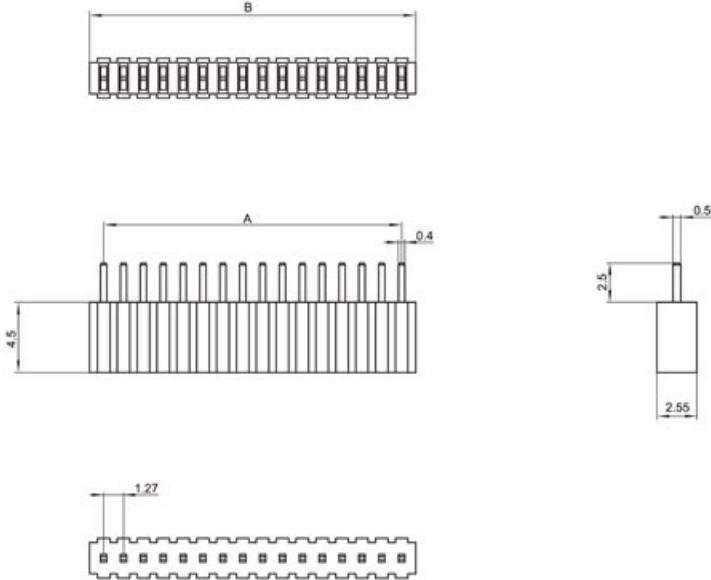

Poles	Type	Size(mm)	
		A	B
2	Du Pont1.27-2A	1.27	3.07
3	Du Pont1.27-3A	2.54	4.34
4	Du Pont1.27-4A	3.81	5.61
5	Du Pont1.27-5A	5.08	6.88
6	Du Pont1.27-6A	6.35	8.15
7	Du Pont1.27-7A	7.62	9.42
8	Du Pont1.27-8A	8.89	10.69
9	Du Pont1.27-9A	10.16	11.96
10	Du Pont1.27-10A	11.43	13.23
11	Du Pont1.27-11A	12.7	14.5
12	Du Pont1.27-12A	13.97	15.77
13	Du Pont1.27-13A	15.24	17.04
14	Du Pont1.27-14A	16.51	18.31
15	Du Pont1.27-15A	17.78	19.58
16	Du Pont1.27-16A	19.05	20.85
17	Du Pont1.27-17A	20.32	22.12
18	Du Pont1.27-18A	21.59	23.39
19	Du Pont1.27-19A	22.86	24.66
20	Du Pont1.27-20A	24.13	25.93

点击次数: 1640 发布时间: 2010-6-14 【打印】 【返回】

产品订购