

SPECIFICATION:

Current Rating: 3.0AMP
 Contact Resistance: 20m Ω (max)
 Insulation Resistance: 1000M Ω Min at 500V DC
 Dielectric Strength: 500V AC Per 1 Minute
 Operating Temperature: -40°C TO +105°C


MATERIALS:

Insulator: P.B.T.+30% Glass Fibre(UL 94V-0)
 Contact: Brass
 Contact plated: 0.8u" Gold Over Nickel

Poles	Part No.	Dimension mm		
		A	B	C
8	310S-8P	29.36	7.62	16.06
10	310S-10P	31.90	10.16	18.60
12	310S-12P	34.44	12.70	21.14
14	310S-14P	36.98	15.24	23.68
16	310S-16P	39.52	17.78	26.22
18	310S-18P	42.06	20.32	28.00
20	310S-20P	44.60	22.86	31.30
24	310S-24P	49.68	27.94	36.38
26	310S-26P	52.22	30.48	38.92
30	310S-30P	57.30	35.56	44.00
34	310S-34P	62.38	40.64	49.08
40	310S-40P	70.10	48.28	56.70
50	310S-50P	82.70	60.96	69.40
60	310S-60P	95.40	73.66	82.10
64	310S-64P	100.48	78.74	87.18


TOLERANCE TABLE

.0	±0.30
.00	±0.20
.000	±0.05

APPROVED:	DATE:	 深圳市灿科盟实业有限公司 CHANKEMENG INDUSTRY CO., LTD
CHECKED:	DATE:	
DRAWN:	DATE:	TITLE: 310S-XP
LYF	2008-04-07	CLIENT P/N: B-3100SXXP-A110
		UNIT: mm
		SCALE: Free
		FILE NO: Chantw-310-00001
		REV: A

深圳市灿科盟实业有限公司
SHENZHEN CHANKEMENG INDUSTRY CO., LTD

筒牛、牛角成品编码规则

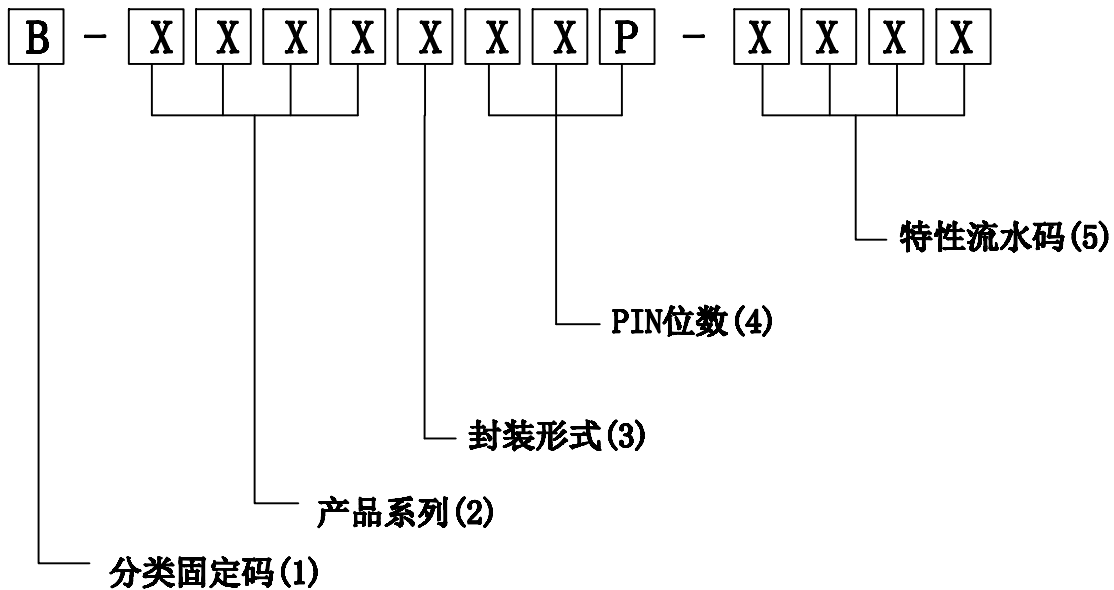

说明:

- (1). 此位数为分类固定码“B”-连接器
- (2). 此数为产品系列,

编码	品名	规格描述
3000	300	筒牛/2.54mm
3001	300-1	筒牛/1.27mm
3002	220-2	筒牛/2.0mm

编码	品名	规格描述
3100	310	牛角/2.54mm
3101	310-1	牛角/1.27mm
3102	310-2	牛角/2.0mm

- (3). 封装形式:

S	直插
R	弯插
M	卧贴
N	立贴

- (4). PIN位数

按实际PIN数编码, 100用“A0”

如: 100位, 编码为“A0P”

- (5). 特性流水码

在规格/描述中, 按步骤指定:

- a) 结构尺寸特性
- b) 塑胶材料特性(颜色+材质)
- c) 五金材料特性(材质+镀层)
- d) 其它特定要求

批 准: _____

审 核: _____

制 定: 龙永峰