





Features

- Application: small portable communication equipment ;
- Contains Pb in sealing glass exempted by RoHS directive;

Frequency Range	32.768KHZ
Equivalent Series Resistance	65KΩMax.
Drive Level	1.0μWMax
Frequency Tolerance (at 25 °C)	± 10 ppm, ± 20 ppm, or specify
The inflection point temperature	+25°C ± 5°C
Frequency temperature coefficient	-0.04 × 10-6 / °C ² Max.
Operating Temperature Range	-10 ~ +60 °C, or specify
Insulation Resistance	500MΩmin./DC100V
Shunt Capacitance (C0)	0.8pF TYP
Load Capacitance	12.5 pF, or specify
Aging (at 25 °C)	± 3 ppm / year Max.
Storage Temperature Range	-20~+70°C, or specify
Packing Unit(包装单位)	3,000pcs/Reel&9,000pcs/Reel

Dimensions

1. Dimensions

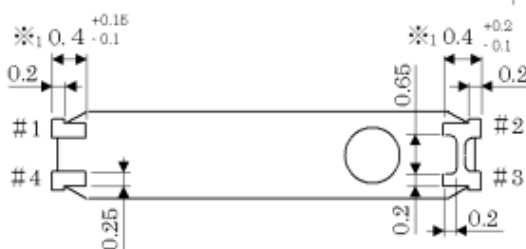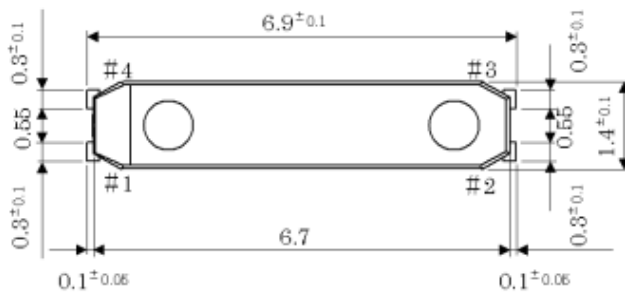

Units: mm