



ROTARY SWITCH

MFR01 SERIES



SPECIFICATION

Rating: 8A 125VAC (CUL)

12A-8(3)A 250V~ μT125/55(ENEC17,CB,CQC)

INITIAL CONTACT RESISTANCE: 20mΩ Max

 
 

 
OPERATION FORCE: 600±300gf-cm


INSULATION RESISTANCE: 100mΩ MIN 500VDC

WITHSTAND VOLTAGE: 1000VAC FOR 1MINUTE

 
ENDURANCE: 10,000CYCLES




POSITION OPTION		TERMINAL TYPE
00	1 POSITIONS	S 
01	2 POSITIONS	
02	3 POSITIONS	P 
03	4 POSITIONS	
04	5 POSITIONS	
05	6 POSITIONS	T 
06	7 POSITIONS	
07	8 POSITIONS	L 
*08	9 POSITIONS	
*10	10 POSITIONS	
C1	5 POSITIONS	
C2	3 POSITIONS	
C3	5 POSITIONS	
92	4 POSITIONS	

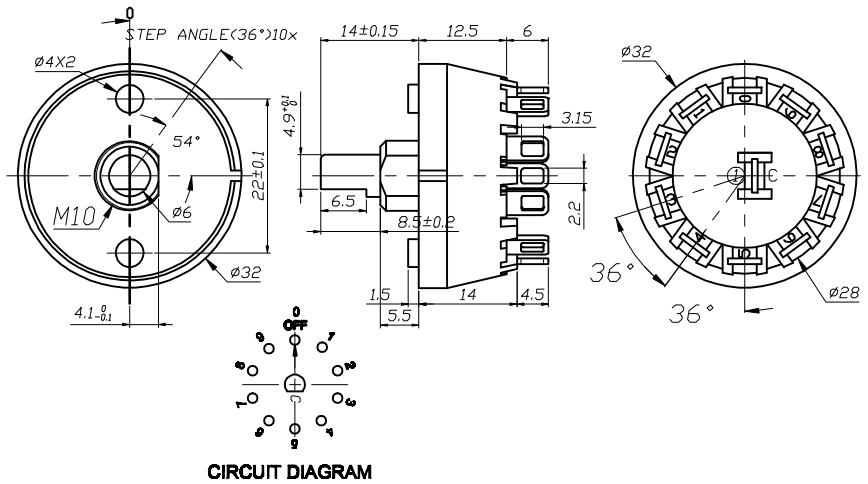

Terminal list



PANEL CUTOUT

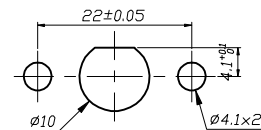

MFR01 SERIES ORDERING SYSTEM

 
 
 
 
MFR01 - A 1 F 0 5 L 1 A S N - R

 
MODEL NO.





STEP ANGLE	
A1	36°
A2	45°

FUNCTION TYPE	
F	NORMAL
M	MOMENTARY (NON-LOCK)

POSITION OPTION	
00	1 POSITIONS
01	2 POSITIONS
02	3 POSITIONS
03	4 POSITIONS
04	5 POSITIONS
05	6 POSITIONS
06	7 POSITIONS
07	8 POSITIONS
*08	9 POSITIONS
*10	10 POSITIONS
C1	5 POSITIONS
C2	3 POSITIONS
C3	5 POSITIONS
92	4 POSITIONS

SHAFT OPTIONS	
L1	
L2	
L3	
L4	

HOUSING TYPE	
A	

TERMINAL TYPE	
S	
P	
T	
L	

ACCESSORIES	
N	No Hex Nut
	With Hex Nut (Unmounted)

RoHS COMPLIANCE	
R	RoHS COMPLIANCE
	NONE

* 1.STEP ANGLE A1:POSITION 08,10 ARE NOT AVAILABLE FOR MOMENTARY FUNCTION TYPE
 2.STEP ANGLE A2:POSITION 06,07,08,10,C1,C2 ARE NOT AVAILABLE FOR MOMENTARY FUNCTION TYPE