



ADSL Line Transformer Through Hole Magnetics




- ADSL Transformer
- RoHS compliance product
- EN60950 Basic Insulation Compliant-250Vrms
- Operating temperature range:-40⁰C to +85⁰C

Electrical Specifications @ 25°C





Part Number	Turns Ratio	OCL @10KHz 100mV 1-5 (2-4 short)	LL @100KHz 100mV 1-5 (2-4, 6-7-9-10)	DCR(Ω max)				THD @30KHz 4.5 V	Hi-Pot
				1-4	2-5	9-6	10-7		
TDA002	1.6: 1±2%	410uH ±5%	10 uH max	1.0	1.0	0.40	0.35	-80dB MAX.	1875/1S/1mA

Mechanical

Schematics

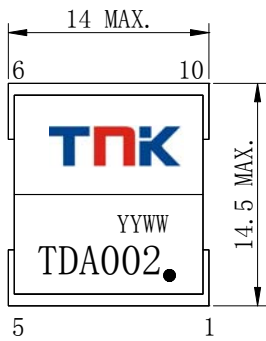

PIN3 拔掉

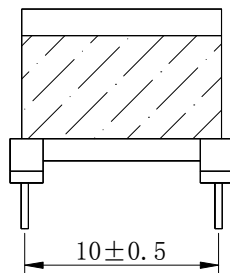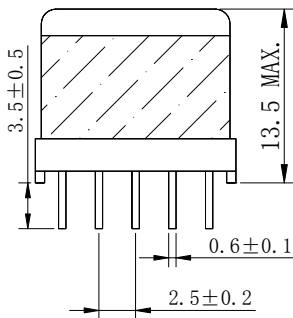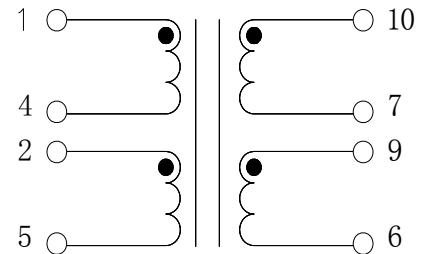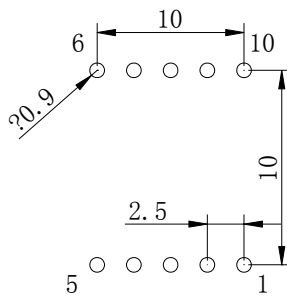

NOTE:

- 1、Units:mm;
- 2、PIN3 are removed;
- 3、Unies otherwise specified all tolerances are:±0.25mm;

东莞市讯康电子科技股份有限公司

地址：广东省东莞市塘厦镇林村里牙塘工业区 145 号

TEL:(86)769-87923451

FAX:(86)769-87923450

WEBSITE:http://www.tnk.net.cn