






- + VDSL Transformer
- + RoHS compliance product
- + EN60950 Basic Insulation Compliant-250Vrms
- + Operating temperature range:-40°C to +85°C

Electrical Specifications @ 25°C

Part Number	Turns Ratio	OCL @10KHz 0.1V	LL @1MHz 0.1V	CWW @100KHz 0.1V	DCR		THD @30KHz 3.0 V	Hi-Pot
	1-4: 10-7 (2-3, 8-9 short)	1-4 (2-3 short)	1-4 (2-3, 7-8-9-10short)	1-10 (2-3, 8-9 short)	1-4 (2-3 short)	10-7 (8-9 short)	1-4TO10-7 (2-3, 8-9 short)	1,2-10,9
TDA149	2:1±5%	420uH ±10%	1.5 uH max	120PF	2.0Ω MAX.	1.0Ω MAX.	-85dB MAX	1875VAC/2S/1mA

Mechanical

Schematics

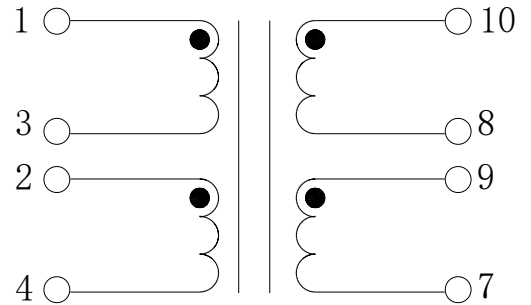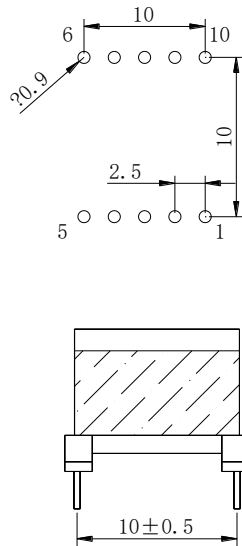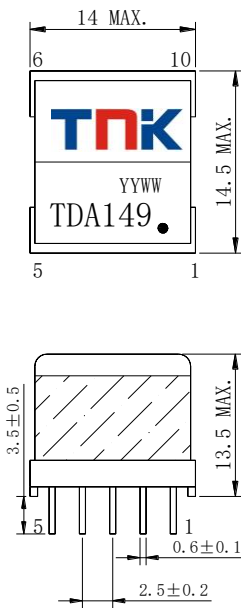

NOTE:

- 1、Dimensions:mm;
- 2、 Unless otherwise specified,tolerances:±0.25(mm);