


MODEL CODE

SS-12D28-XX

Knob Type	H (mm)
L	3 ~ 12
G	

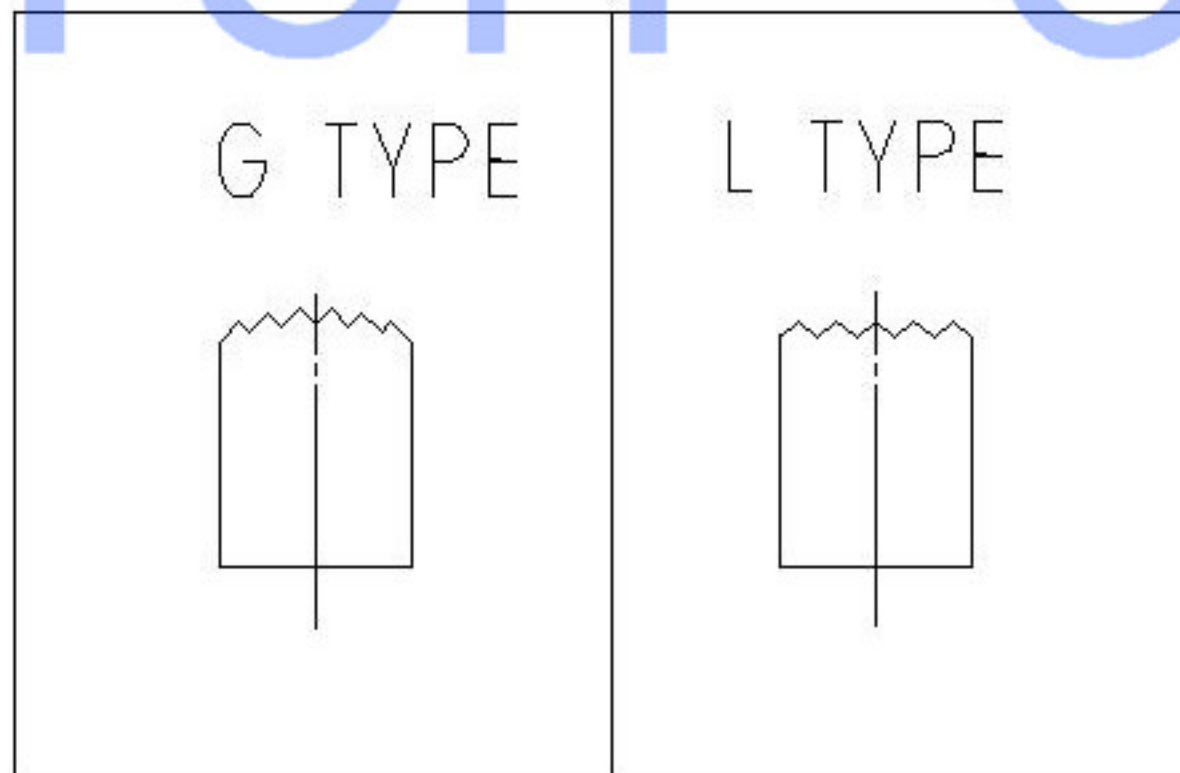

Typical Specifications

1. Rating : 5A120V AC
2. Insulation Resistance: 1,000M min
3. Dielectric Strength: 1,500V RMS
4. Operating Life : 10,000 cycles

ITEM	PAPT NAME	TER.NO	QTY	MATERIAL	FINISHING	REMARK
⑤	Terminal	—	3	Copper Alloy	silver plated	—
④	Contact	—	1	Copper Alloy	silver plated	—
③	Housing	—	1	Stainless Steel		—
②	Slide Handle	—	1	Nylon		—
①	Case	—	1	Diallyl Phthalate (DAP)		—

MARK	DESCRIPTION	DATE	REVISED	APPROVED	ANGLAR	±5°	DSND	DATE	SCALE: N/A	MODEL TYPE: SLIDE SWITCH			
ΔX					X.X	±0.2mm	DWN	DATE	VIEW:	PART NO.:			
ΔX					X.XX	±0.1mm	CHKD	DATE	UNIT: mm	DWG NO.:			
ΔX					X.XXX	±0.05mm	APPD	DATE	SIZE: A4	SS-12D28-XX			
REVISIONS							UNSPECIFIED TOLERANCES		XKB INDUSTRIAL PRECISION CO.,LIMITED		WEIGHT	SHEET	REVISION
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn											1.0g	1/1	A0