

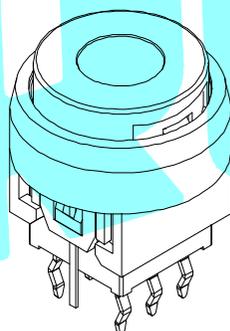


Color	VR	IF	Recommended Operating	IF	
				Nom	Max
White	DC5V	20mA	20mA	3.0V	3.6V
Red	DC5V	20mA	20mA	1.7V	2.4V
Yellow	DC5V	20mA	20mA	1.9V	2.4V
Blue	DC5V	20mA	20mA	3.0V	3.6V
Green	DC5V	20mA	20mA	1.9V	2.4V

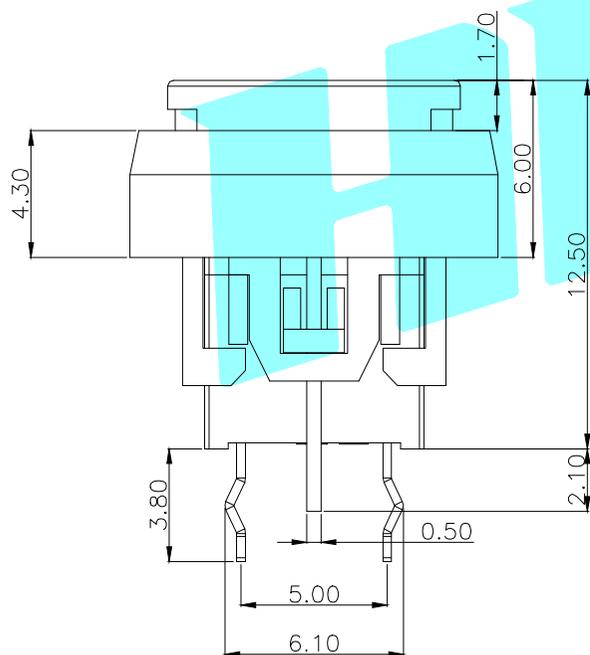

PCBLayout(Pattern Side)

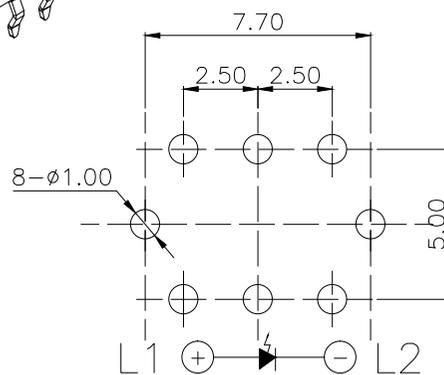

LED colour(LED颜色)	Part No. 料号
White(白色)	K6-6136D-□□-01
Red(红色)	K6-6136D-□□-02
Blue(蓝色)	K6-6136D-□□-03
Green(绿色)	K6-6136D-□□-04
Yellow(黄色)	K6-6136D-□□-05
Yellow/White(黄色/白色)	K6-6136D-□□-11

NO.	Operating Type	Part No.
1	Push To Lock(自锁)	K6-6136D-L1-□□
2	Push No Lock(无锁)	K6-6136D-N1-□□

②	Terminal	3	Phosphor bronze	Au Plating		
①	Housing	1	Nylon	Black		
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK

APPROVALS		DATE	HRO 翰睿® ELECTRONICS CO.,LTD		
DRAWN	J.X.Zhang	2013/11/11	TITLE:	LED Tact Switch	
CHECKED			PART NO.	K6-6136D-□□-□□	
APPROVALS			UNIT: mm	SCALE: 1:1	PROJ:
TOLERANCES ARE		30~以上 ±0.30	ANGLE	DRAWING NO.	SHEET 1 OF 1
		10~30 ±0.20			
		5~10 ±0.15			
		~ 5 ±0.10			

ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.
	A		NEW			