


GPSR1040-Series

GPSR系列產品符合“實用新型-貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8



實物圖:



 
推薦焊盤:



尺寸: (Unit:mm)

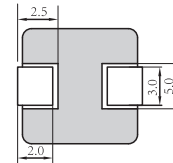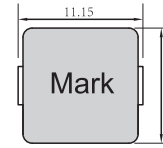



命名方式:

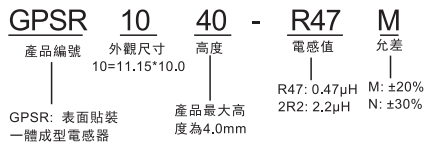

特性參數:

Part Number 型號	Inductance 電感量(μH) @100KHz,1V	DC Resistance 直流電阻(mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR1040-R36M	0.36	1.7	2.2	30	50
GPSR1040-R47M	0.47	2.6	3.3	25	33
GPSR1040-R56M	0.56	2.6	3.3	25	33
GPSR1040-R68M	0.68	2.7	3.5	18	30
GPSR1040-1R0M	1.0	3	3.3	18	28
GPSR1040-1R5M	1.5	3.8	4.2	16	25
GPSR1040-2R2M	2.2	6	7	10	18
GPSR1040-3R3M	3.3	10.8	11.8	9	14
GPSR1040-5R6M	5.6	20	23	7.5	14
GPSR1040-6R8M	6.8	22.5	25	6.5	9
GPSR1040-100M	10	27.5	30	6	8
GPSR1040-150M	15	53	70	3.6	6
GPSR1040-220M	22	73	92	4	6
GPSR1040-330M	33	136	177	3	5

典型電流重疊與溫升特性曲線

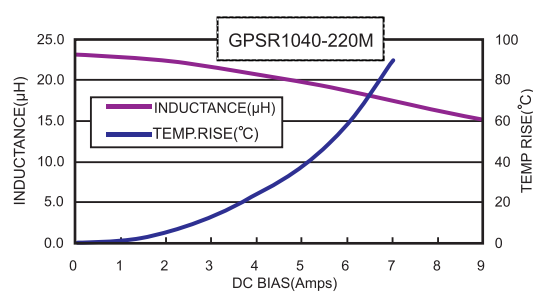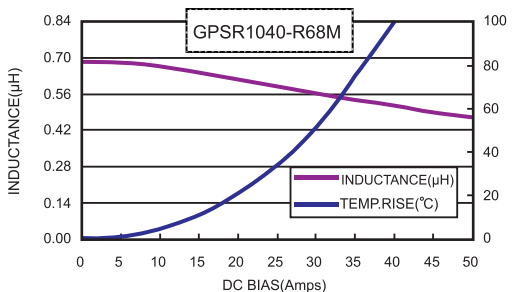

一體貼片電感器

一體直插電感器

磁膠貼片電感器

注塑貼片電感器

繞線貼片電感器

繞線直插電感器

疊層電感器

可靠性測試

電感基礎知識

免責聲明