

FEATURES

- ※ 1.65mm above PCB
- ※ High solder strength

APPLICATION


- ※ Personal audio
- ※ Mobile phone
- ※ Audio, OA equipment

SPECIFICATION


Contact Rating	20mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160±50gf
Travel	0.2mm
Operating Life	100,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +90°C

HOW TO ORDER

TCEPQR

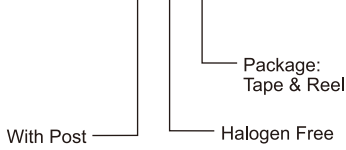

CIRCUIT

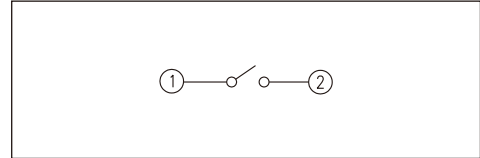

PACKAGE

<Tape & Reel>
3000 pcs

TACT SWITCH

TCE

