



GPSR0750-Series

GPSR系列產品符合“實用新型-貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8



實物圖:

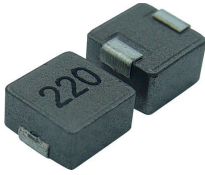


推薦焊盤:

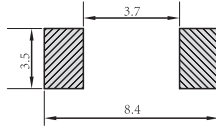

尺寸: (Unit:mm)

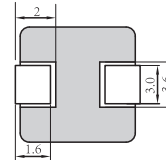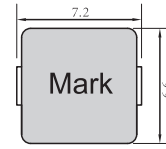



命名方式:

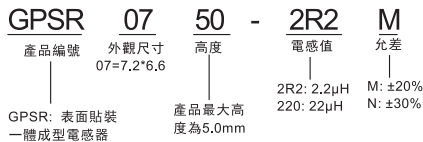

特性參數:

Part Number 型號	Inductance 電感量 (μH) @100KHz, 1V	DC Resistance 直流電阻 (mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR0750 -R36M	0.36	3.2	3.5	21	25
GPSR0750 -R56M	0.56	3.4	3.6	20	18
GPSR0750 -R68M	0.68	3.9	4.2	18	17
GPSR0750 -R82M	0.82	4.6	4.9	16.5	16
GPSR0750 -1R0M	1	6.5	8.5	10	16
GPSR0750 -1R5M	1.5	8.5	12	8	14
GPSR0750 -2R2M	2.2	11	14	7	12
GPSR0750 -3R3M	3.3	18	22	6.5	11
GPSR0750 -4R7M	4.7	22	30	6	10
GPSR0750 -6R8M	6.8	33	45	4.5	9
GPSR0750 -220M	22	108	140	2.2	4
GPSR0750 -330M	33	160	210	2	4
GPSR0750 -470M	47	192	247	2	3

典型電流重疊與溫升特性曲線

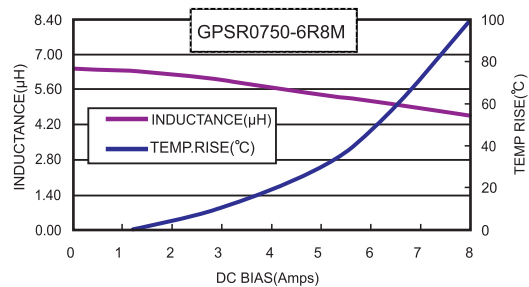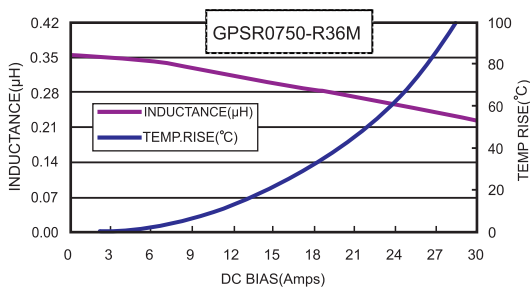

一體貼片電感器

一體直插電感器

磁膠貼片電感器

注塑貼片電感器

繞線貼片電感器

繞線直插電感器

疊層電感器

可靠性測試

電感基礎知識

免責聲明