


GPSR0520-Series

GPSR系列產品符合“實用新型貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8




實物圖:




推薦焊盤:

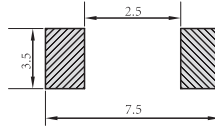

尺寸: (Unit:mm)

 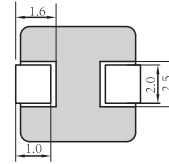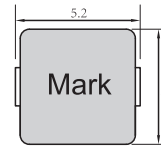

命名方式:

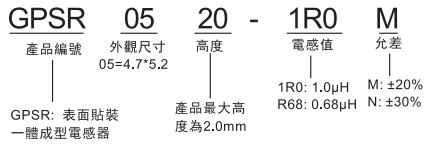

特性參數:

Part Number 型號	Inductance 電感量(μH) @100KHz, 1V	DC Resistance 直流電阻(mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR0520-R68M	0.68	15	20	5	10
GPSR0520-1R0M	1	15	21	5	8
GPSR0520-1R2M	1.2	17	27	5	8
GPSR0520-1R5M	1.5	20	26	4	6
GPSR0520-2R2M	2.2	32	42	3.5	6
GPSR0520-3R3M	3.3	44	58	3.5	5.5
GPSR0520-4R7M	4.7	68	90	3.2	4.5
GPSR0520-5R6M	5.6	75	97	3	4
GPSR0520-100M	10	170	221	2	3

典型電流重疊與溫升特性曲線

