


GPSR0530-Series

GPSR系列產品符合“實用新型貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8




實物圖：




推薦焊盤：

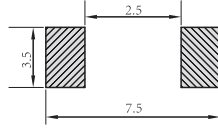

尺寸：(Unit:mm)

 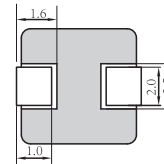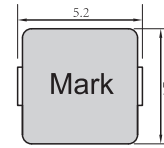

命名方式：

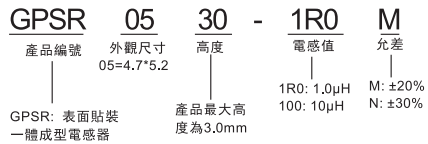

特性參數：

Part Number 型號	Inductance 電感量(μH) @100KHz,1V	DC Resistance 直流電阻(mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR0530-R68M	0.68	11	18	5	8
GPSR0530-1R0M	1	13	22	4	7
GPSR0530-1R5M	1.5	20	25	4	7
GPSR0530-2R2M	2.2	26.5	40	4	7
GPSR0530-3R3M	3.3	30	42	4	7
GPSR0530-4R7M	4.7	46	60	3	4.5
GPSR0530-5R6M	5.6	62	80	3	4
GPSR0530-6R8M	6.8	78	108	2.5	4
GPSR0530-100M	10	115	150	2	4

典型電流重疊與溫升特性曲線

