



GPSR0630-Series

GPSR系列產品符合“實用新型-貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8



實物圖:

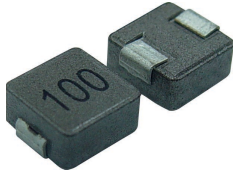


推薦焊盤:

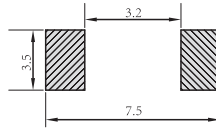

尺寸: (Unit:mm)

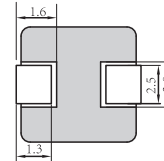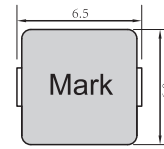

命名方式:

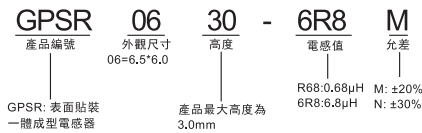

特性參數:

Part Number 型號	Inductance 電感量 (μH) @100KHz, 1V	DC Resistance 直流電阻 (mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR0630-R68M	0.68	12	16	11	16
GPSR0630-1R5M	1.5	16	22	9	12
GPSR0630-2R2M	2.2	17	20	8	11
GPSR0630-2R7M	2.7	25	34	6	8
GPSR0630-3R3M	3.3	32	45	5	7
GPSR0630-4R7M	4.7	34	45	5.5	7
GPSR0630-5R6M	5.6	54	70	5	7
GPSR0630-6R8M	6.8	63	84	4.5	6
GPSR0630-100M	10	75	100	4	6

典型電流重疊與溫升特性曲線

