


环保物料

TEL: 0769-82001899

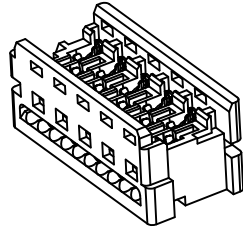



电气性能：  
 额定电流：1.0Amp  
 最大耐受电压：AC 250V/1Minute  
 绝缘电阻：1000M Min/DC 500V  
 接触电阻：20m Max  
 工作温度：-20 °C +105 °C

MATERIAL & FINISH


Insulator: PBT Glass Fiber(UL94V-0)  
 COLOUR WHITE.

Contact : Phosphor Bronze


Contact : Nickel.

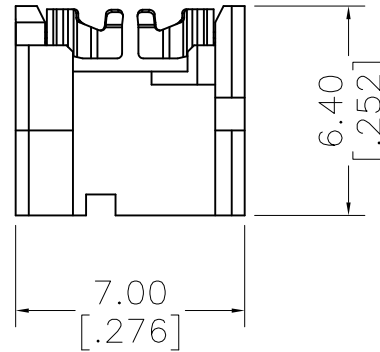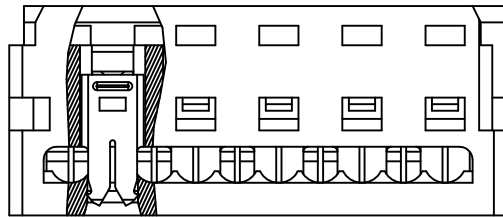

1.27 mm Ribbon Cable

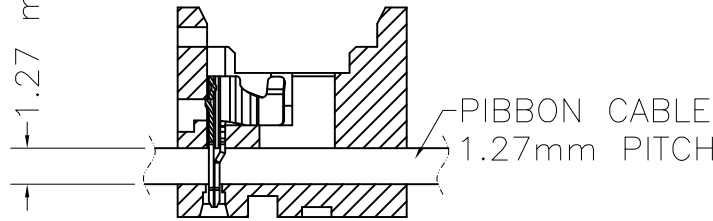

SECTION SHOWING

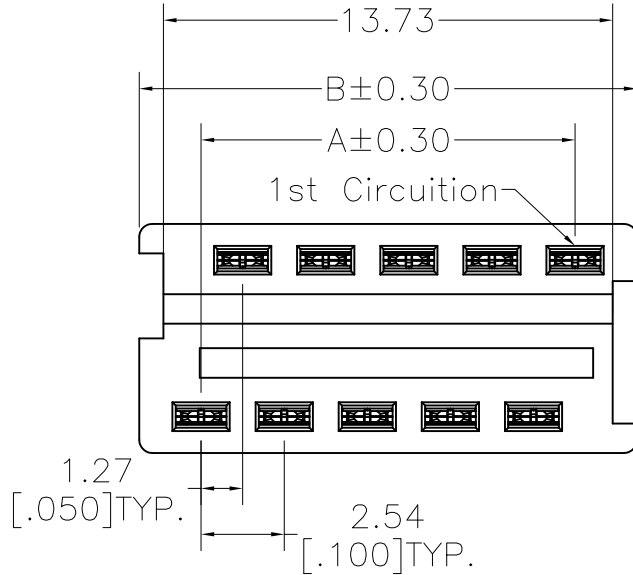

26	(31.75)/1.250	(35.53)/1.399
24	(29.21)/1.150	(32.99)/1.299
22	(26.67)/1.050	(30.45)/1.199
20	(24.13)/.950	(27.91)/1.099
18	(21.59)/.850	(25.37)/.999
16	(19.05)/.750	(22.83)/.899
14	(16.51)/.650	(20.29)/.799
12	(13.97)/.550	(17.75)/.699
10	(11.43)/.450	(15.21)/.599
8	(8.89)/.350	(12.67)/.499
6	(6.35)/.250	(10.13)/.399
4	(3.81)/.150	(7.59)/.299
CCT SIZE	DIMENSION A	DIMENSION B

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	XFCN兴飞连接器有限公司 CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	1.27mm IDC Style Connectors	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	I1276-XX-N0	
				.XXX	±0.03	.XXX°	±0.5°			DWG. NO.	009
AO	MODIFICATION	DRAW	DATE								