

MINI SLIDE SWITCH

NEW

NSI-10
Series



General Specification

1. **Rating :** DC 12V 0.5A~24V 0.3A
2. **Contact Resistance :** 30mΩ Max.
3. **Insulation Resistance :** Min 10,000 MΩ at DC 500V
4. **Operating Force :** 250gf ±150gf
5. **Travel :** 1.6mm
6. **Life Cycle :** 2,000 cycle(with load)

HOW TO ORDER

NSI

 
Type

NSI SMD Type

Slider


Slider

- Slider 1.4mm



-

 L Slider 2.8mm



10

Circuit




10 Change over Type

Terminal

Terminal

S SMD Type of Vertical
HS SMD Type of Angle

NSI-10S Type(Change over)

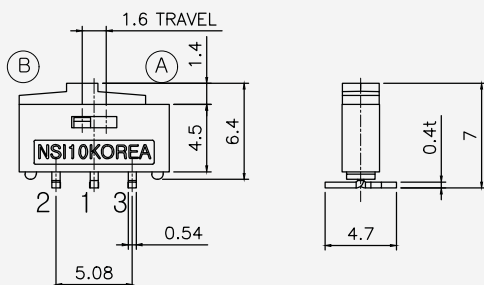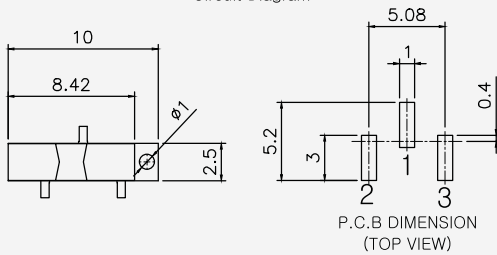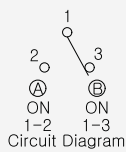

NSI-10HS Type(Change over)

