

PRODUCT DISPLAY




PRODUCT SIZE

Front



Side

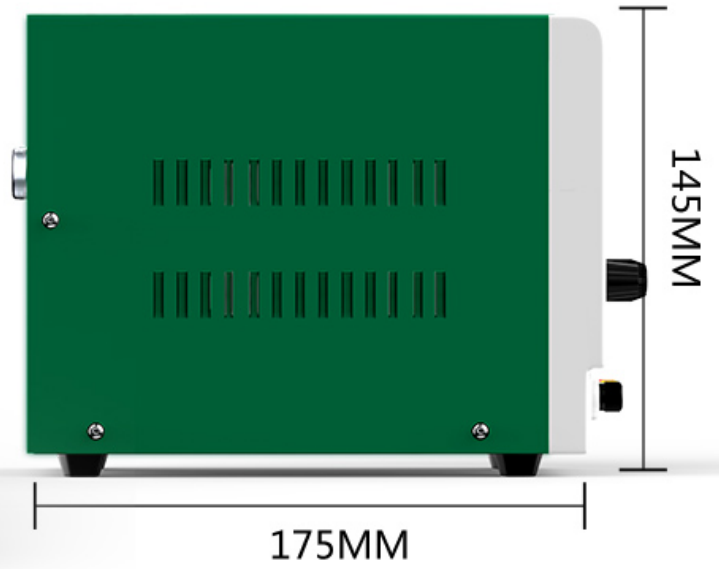


PRODUCT DETAILS

Current output indication
(0-3A)

Voltage output indication
(0-20V)



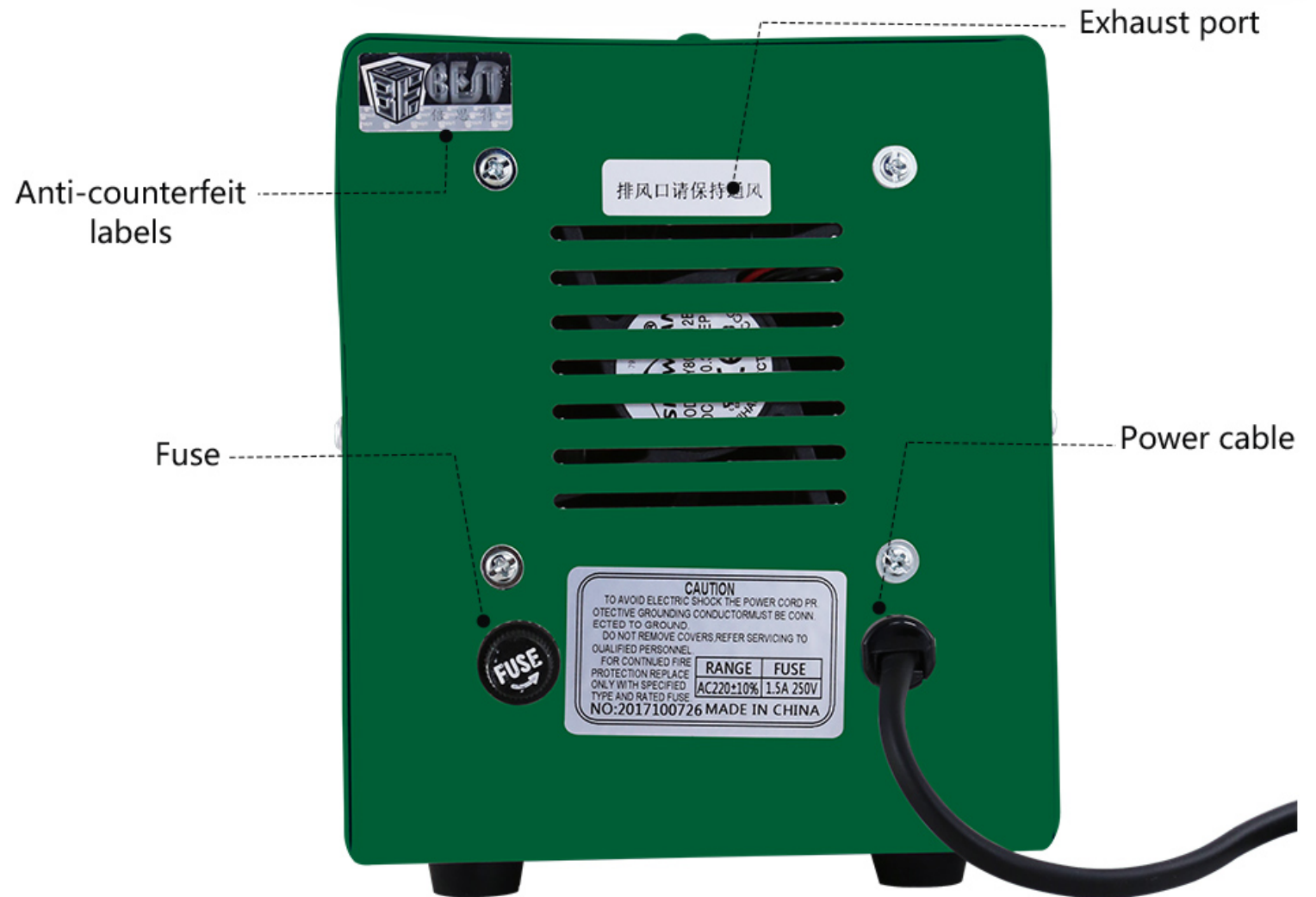

Exhaust port

Anti-counterfeit labels


排风口请保持通风

Fuse


Power cable

CAUTION
TO AVOID ELECTRIC SHOCK THE POWER CORD PROTECTIVE GROUNDING CONDUCTOR MUST BE CONNECTED TO GROUND.
DO NOT REMOVE COVERS REFER SERVICING TO QUALIFIED PERSONNEL.
FOR CONTINUED FIRE PROTECTION REPLACE ONLY WITH SPECIFIED TYPE AND RATED FUSE.
NO:2017100726 MADE IN CHINA

RANGE	FUSE
AC220±10%	1.5A 250V

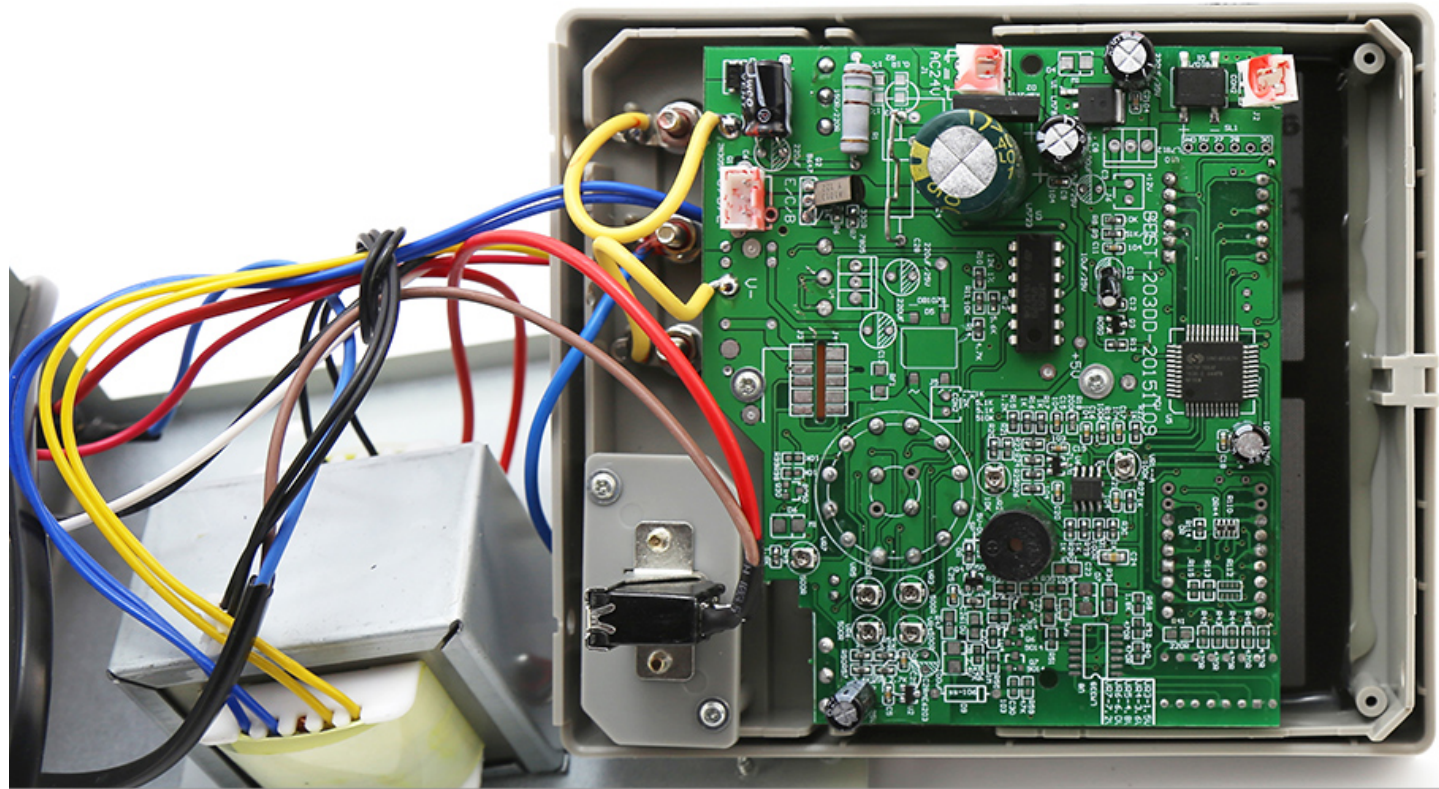

▲ PCB integrated motherboard double-sided chip technology

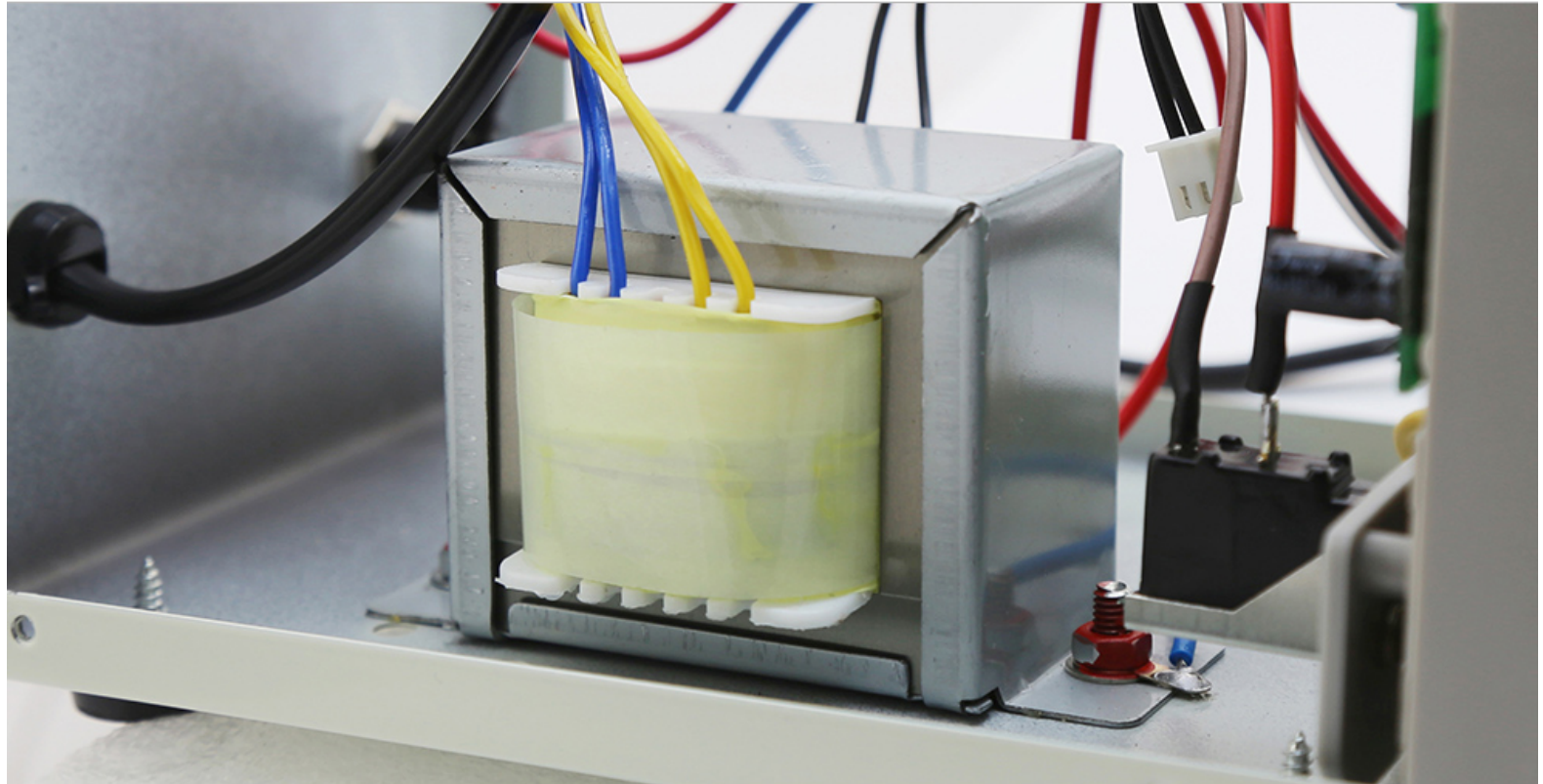

▲ High Power, Pure copper transformer

Rated working conditions

voltage	220v ± 10%
working environment	-10 °C ~ 40 °C Relative humidity: <90%
Storage environment	-20 °C ~ 40 °C Relative humidity: <80%
Corrugated factor	<= 0.5mvr (5Hz-1MHz) Iomax> 1A
Features	Short circuit protection / overload protection / alarm function / continuity test / automatic recovery

Regulated working conditions

Power stability	$\leq 0.01\% + 2\text{mV}$
Load stability	$\leq 0.01\% + 2\text{mV}$ ($I_{\text{max}} < 1\text{A}$)
Recovery Time	$\leq 100\mu\text{s}$ (maximum current $\leq 3\text{A}$)

Specifications

Model	PS-1502D+	PS-203D
Body weight	1.6KG	2.2KG
Dimensions	125MM*175MM*145MM	
Voltage and current	0-15V/0-2A	0-20V/0-3A
Features	Short circuit protection, automatic recovery, voltage test, on-off test	
GSM signal detection	<input checked="" type="checkbox"/> Can detect RF signals	
Overload protection current	2A	
Voltage display accuracy	0.1V	
Current display accuracy	0.01A	
Mobile signal strength indicator	Have	
Brush power supply function	No	
Smart cooling	No	Have

PRODUCT PACKAGING

WEIGHT:2.2KG



标签：五金工具