


产品详细信息 introduce

扁平连接器 >> FPC1.0-1

产品订购

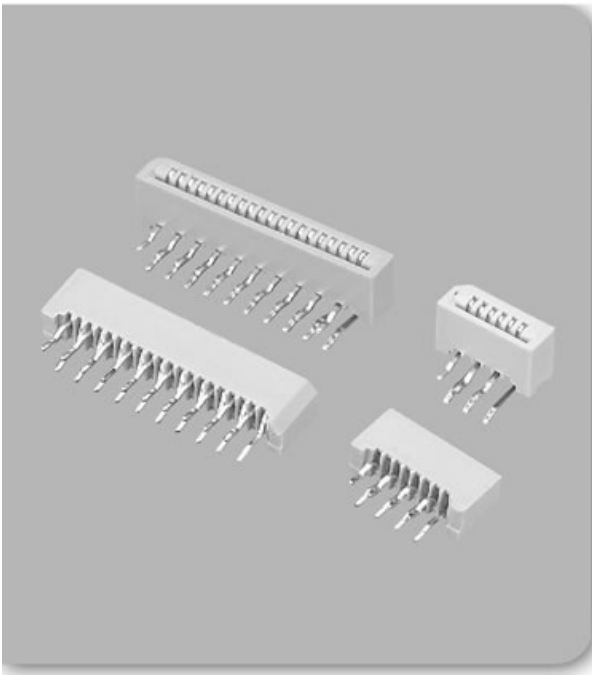



SPECIFICATIONS

Unit:mm

- ◇ Poles: 4~35
- ◇ Applicable wire: AWG#28-#22
- ◇ Voltage rating: 50V DC/AC
- ◇ Current rating: 0.5A
- ◇ Withstand voltage: 500V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 500MΩ
- ◇ Contact resistance: ≤ 0.03Ω
- ◇ Applicable PC board thickness: 0.6~1.2mm


UL:Recognized No.E309635
RoHS-specification and Halogen-free products






FPC 1.0-1-nP 立插

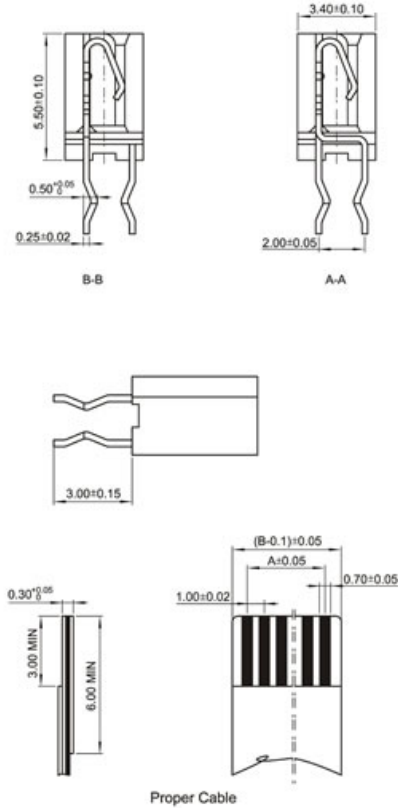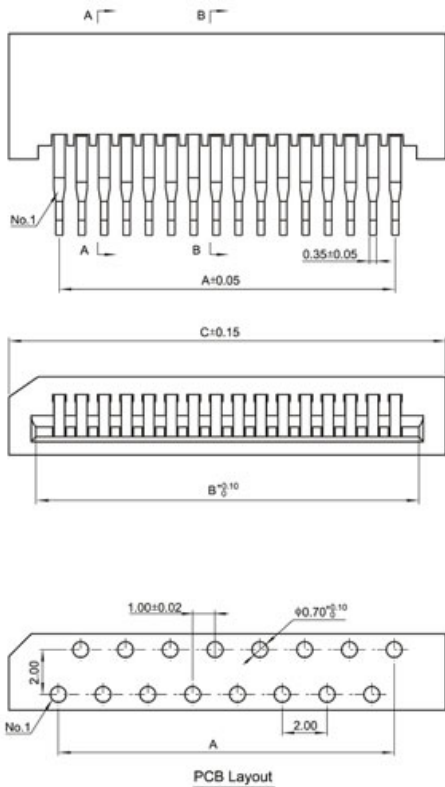


FPC 1.0-nP 卧插

Unit:mm

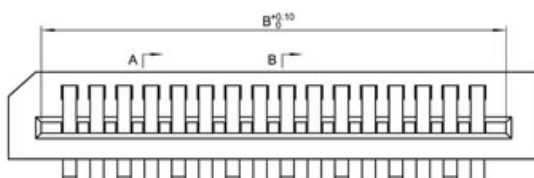

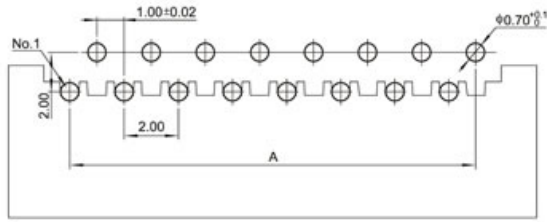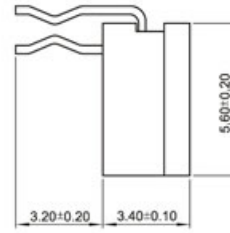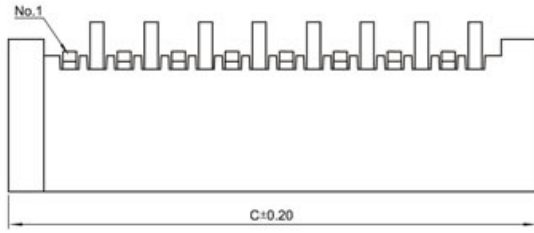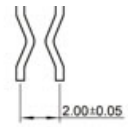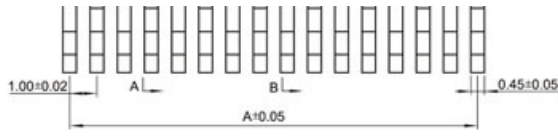

PCB Layout

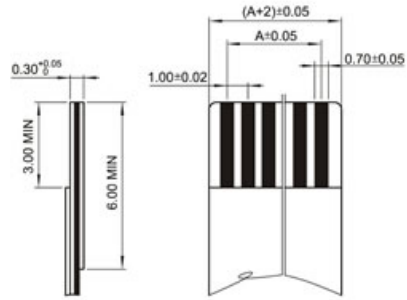

Proper Cable

Poles	Type	Size(mm)		
		A	B	C
4	FPC 1.0-1-4Y	3.0	5.1	7.4
5	FPC 1.0-1-5Y	4.0	6.1	8.4
6	FPC 1.0-1-6Y	5.0	7.1	9.4
7	FPC 1.0-1-7Y	6.0	8.1	10.4
8	FPC 1.0-1-8Y	7.0	9.1	11.4
9	FPC 1.0-1-9Y	8.0	10.1	12.4
10	FPC 1.0-1-10Y	9.0	11.1	13.4
11	FPC 1.0-1-11Y	10.0	12.1	14.4
12	FPC 1.0-1-12Y	11.0	13.1	15.4
13	FPC 1.0-1-13Y	12.0	14.1	16.4
14	FPC 1.0-1-14Y	13.0	15.1	17.4

Poles	Type	Size(mm)		
		A	B	C
15	FPC 1.0-1-15Y	14.0	16.1	18.4
16	FPC 1.0-1-16Y	15.0	17.1	19.4
17	FPC 1.0-1-17Y	16.0	18.1	20.4
18	FPC 1.0-1-18Y	17.0	19.1	21.4
19	FPC 1.0-1-19Y	18.0	20.1	22.4
20	FPC 1.0-1-20Y	19.0	21.1	23.4
21	FPC 1.0-1-21Y	20.0	22.1	24.4
22	FPC 1.0-1-22Y	21.0	23.1	25.4
23	FPC 1.0-1-23Y	22.0	24.1	26.4
24	FPC 1.0-1-24Y	23.0	25.1	27.4
25	FPC 1.0-1-25Y	24.0	26.1	28.4

Poles	Type	Size(mm)		
		A	B	C
26	FPC 1.0-1-26Y	25.0	27.1	29.4
27	FPC 1.0-1-27Y	26.0	28.1	30.4
28	FPC 1.0-1-28Y	27.0	29.1	31.4
29	FPC 1.0-1-29Y	28.0	30.1	32.4
30	FPC 1.0-1-30Y	29.0	31.1	33.4
31	FPC 1.0-1-31Y	30.0	32.1	34.4
32	FPC 1.0-1-32Y	31.0	33.1	35.4
33	FPC 1.0-1-33Y	32.0	34.1	36.4
34	FPC 1.0-1-34Y	33.0	35.1	37.4
35	FPC 1.0-1-35Y	34.0	36.1	38.4

点击次数: 2862 发布时间: 2010-6-14 [【打印】](#) [【返回】](#)

