


KJN SFTY X1-440 Y1-400, Ceramic, 1000 pF, 20%, 440 VAC (X1), 400 VAC (Y1), Y5U, Lead Spacing = 12.5mm

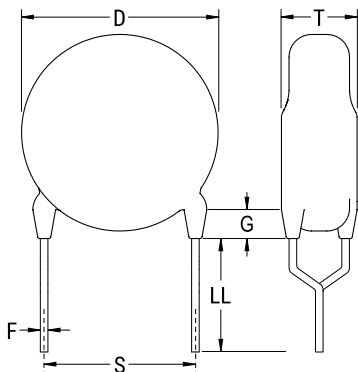

Dimensions	
D	9mm MAX
T	8mm MAX
S	12.5mm MAX
F	0.6mm +/-0.1mm

Packaging Specifications	
Packaging:	T&R, 360mm, H0 = 16mm, Component Pitch = 25.4mm
Packaging Quantity:	300

General Information	
Series:	KJN SFTY X1-440 Y1-400
Style:	Radial Disc
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Qualifications:	ENEC, cUL, CQC, VDE
AEC-Q200:	No

Specifications	
Capacitance:	1000 pF
Capacitance Tolerance:	20%
Voltage AC:	440 VAC (X1), 400 VAC (Y1)
Dielectric Withstanding Voltage:	4000 VDC
Temperature Range:	-25/+85°C
Temperature Coefficient:	Y5U
Insulation Resistance:	10 GOhms
Safety Class:	X1/Y1