


**KEMET Part Number: PMR209MC6100M022R30**  
(P409CE104M250AH220)

PMR209, Film, Metallized Paper, Resistor/Capacitor, 0.1 uF, 20%, 630 VDC, 85°C, Lead Spacing = 20.3mm

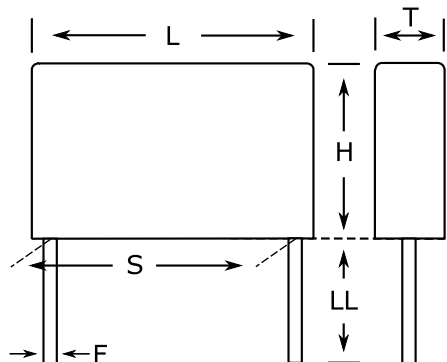

**Dimensions**

L	24mm MAX
H	14mm MAX
T	7.6mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
<b>Packaging Quantity:</b>	250

**General Information**

<b>Series:</b>	PMR209
<b>Dielectric:</b>	Metallized Paper
<b>Style:</b>	Radial
<b>Features:</b>	RC Unit approved
<b>RoHS:</b>	Yes
<b>Lead:</b>	Wire Leads
<b>Qualifications:</b>	ENEC, UL, cUL
<b>AEC-Q200:</b>	No
<b>Construction:</b>	Molded
<b>Miscellaneous:</b>	Resistor= 22 Ohms.
<b>Notes:</b>	Not For New Design, Please Use The New P409 Series @ 275 VAC.

**Specifications**

<b>Capacitance:</b>	0.1 uF
<b>Capacitance Tolerance:</b>	20%
<b>Voltage AC:</b>	250 VAC
<b>Voltage DC:</b>	630 VDC
<b>Temperature Range:</b>	-40/+85°C
<b>Rated Temperature:</b>	85°C
<b>Insulation Resistance:</b>	3 GOhms
<b>Safety Class:</b>	X2