


KEMET Part Number: SMR15225K63B12L4BULK
(F211BM225K063C)

SMR/F211, Film, Metallized PPS, General Purpose, 2.2 uF, 10%, 63 VDC, 125°C, Lead Spacing = 15mm

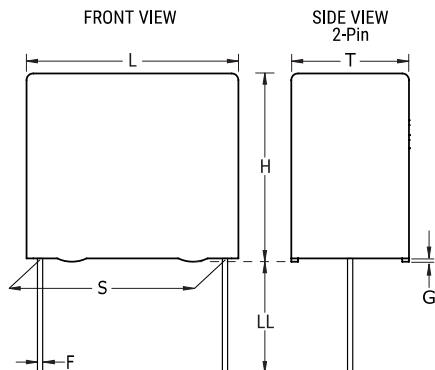

General Information	
Series:	SMR/F211
Dielectric:	Metallized PPS
Style:	Radial
Features:	Audio Applications
RoHS:	Yes
Lead:	Wire Leads
AEC-Q200:	No
Miscellaneous:	The rated voltage decreases 2%/C between +125C and +150C.
Notes:	Case Size = BM.

Dimensions	
L	18mm +0/-0.5mm
H	15mm +0/-0.5mm
T	8mm +0/-0.5mm
S	15mm +/-0.4mm
LL	4mm +1mm
F	0.8mm +/-0.05mm
G	0.5mm NOM

Specifications	
Capacitance:	2.2 uF
Capacitance Tolerance:	10%
Voltage AC:	40 VAC
Voltage DC:	63 VDC
Temperature Range:	-55/+150°C
Rated Temperature:	125°C
Dissipation Factor:	0.15% 1kHz, 0.35% 10kHz
Insulation Resistance:	2.27273 GOhms
Max dV/dt:	6 V/us

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	600