


GPSR0620-Series

GPSR系列產品符合“實用新型.貼片式功率電感器”專利，專利號：ZL 2009 2 0129705.8



實物圖：




推薦焊盤：

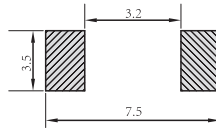

尺寸：(Unit:mm)

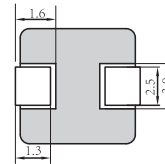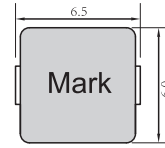

命名方式：

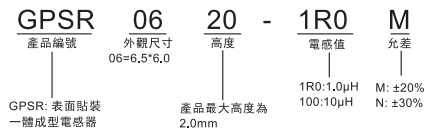

特性參數：

Part Number 型號	Inductance 電感量 (μH) @100KHz,1V	DC Resistance 直流電阻 (mΩ)		Heat Rating Current 溫升電流(A)	Saturation Current 飽和電流(A)
		典型值 Typical	最大值 Max		
GPSR0620-1R0M	1	14	20	6	8
GPSR0620-1R5M	1.5	20	27	5	7
GPSR0620-2R2M	2.2	27	35	4	6
GPSR0620-3R3M	3.3	49	65	3.5	5
GPSR0620-4R7M	4.7	65	90	3	4.5
GPSR0620-6R8M	6.8	106	139	2.5	4
GPSR0620-100M	10	180	240	2	3.5

典型電流重疊與溫升特性曲線

