

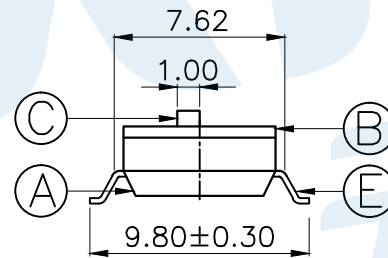
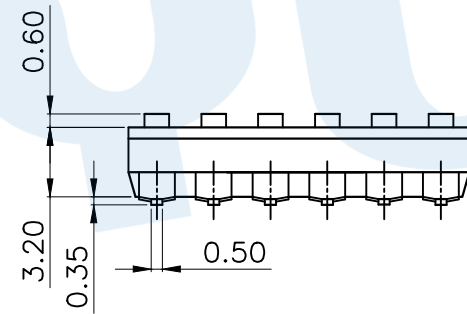
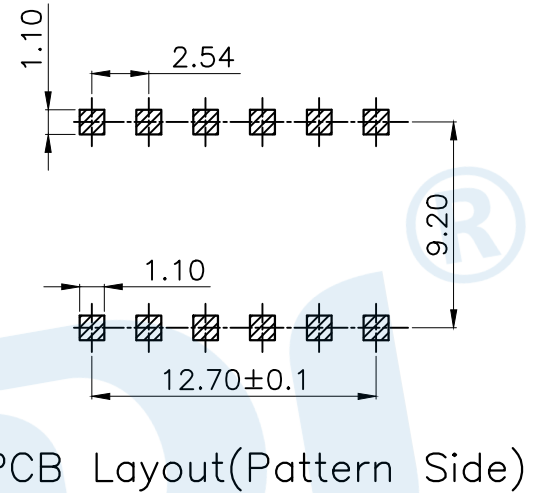
 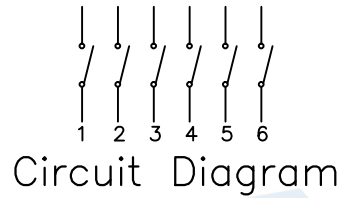


RoHS

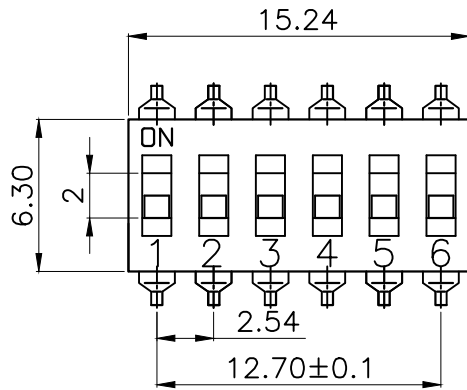

凸柄 Convex handle



短柄 Short handle

NOTE:

- 1.Rating: 24V 25mA DC
- 2.Insulation Resistance:  $\geq 100 \text{ M}\Omega$
- 3.Withstand voltage: AC 500V 1Minute
- 4.Operating Force Range: 500gf Max
- 5.Mechanical Life: 3,000 Cycles

Number of digits(位数)	1P	2P	3P	4P	5P	6P	7P	8P	9P	10P	12P
Cover/black 凸柄 Convex handle	TO-01	TO-02	TO-03	TO-04	TO-05	TO-06	TO-07	TO-08	TO-09	TO-10	TO-12
盖子/黑色 短柄 Short handle	TO-01D	TO-02D	TO-03D	TO-04D	TO-05D	TO-06D	TO-07D	TO-08D	TO-09D	TO-10D	TO-12D

NO.	Name	Number	Qty	Materil	Remarks
Ⓔ	Terminal	12		Brass	Gold plating
Ⓓ	Shrapnel	6		Beryllium copper	Gold plating
Ⓒ	Handle	6		PA46	White
Ⓑ	Cover	1		PPS	Black
Ⓐ	Base	1		PPS	Black

YUANDI® Yuandi Electronics Co, Ltd

design	date	name	DIP SWITCH
Review	date	model	TO-06
Approved	date		

Drawing number: angle  $\pm 2'$  10~30  $\pm 0.30$  5~10  $\pm 0.20$  ~ 5  $\pm 0.10$  Tolerance not specified Proportion 1:1 unit mm gage number A4