



标注前有"\*"重点检验尺寸

# 型号: KH-FPC4G-1.13IPEX-100-6417

图面产品均符合ROHS标准

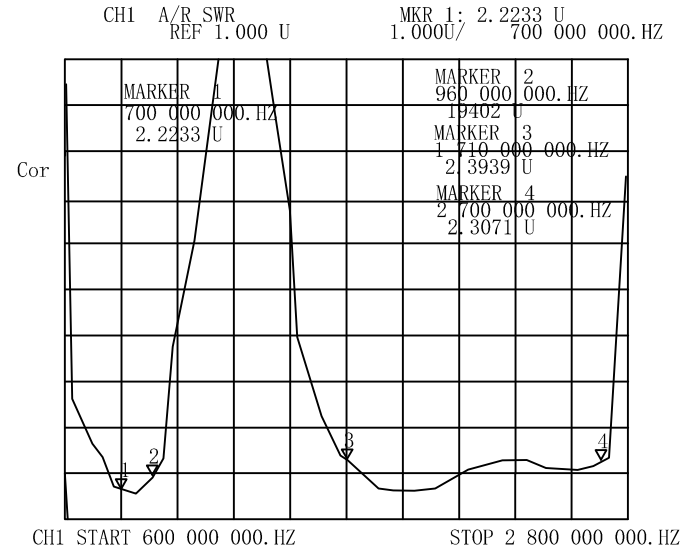

Performance parameters	
Product name	内置天线
Model Type	KH-FPC4G-1.13IPEX-100-6417
Frequency Range	700-960/1710-2700 MHz
Band Width	260/990MHz
Vswr	≤2.5
Gain	2 DBi
Impedance	50 OHM
Polarization	Vertical
Radiation	OMNIDIRECTIONAL
Max power	10 W
Connector	IPEX
Cable	RF1.13-100MM
Dimensions	64 mm *17 mm
material	PI
Temperature	-35 °- 85°
Lighting protection	DC grounding
Weight	

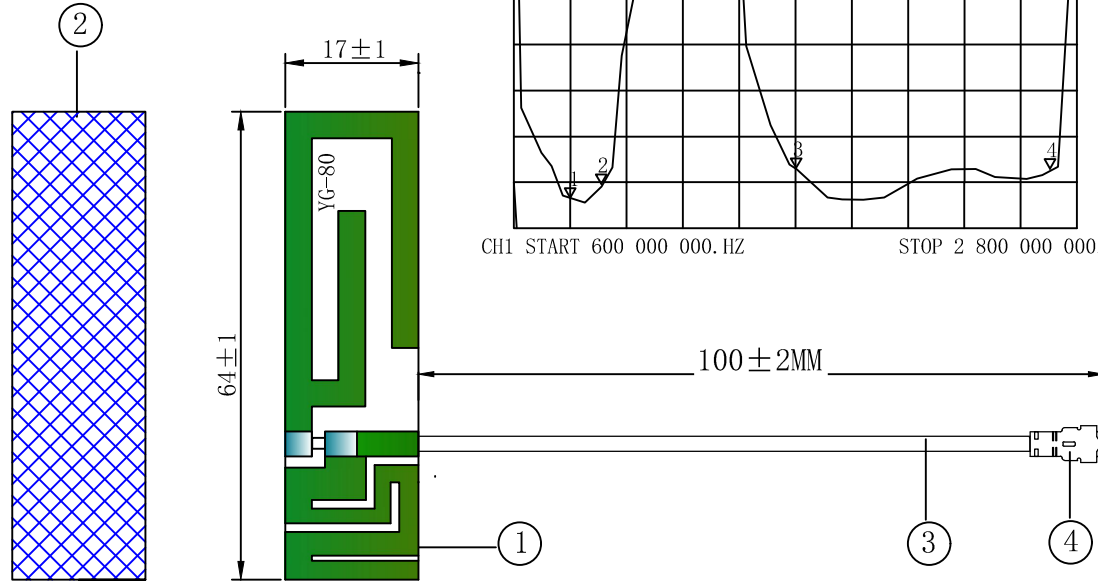


### 部件材质工艺说明:

序号	物料名称	产品描述	数量
①	Antenna element	PI	1
②	Installation method	3M 300LSE	1
③	CABLE	RFφ1.13 COAXIAL CABLE 50ohm BLACK	1
④	CONNECTOR	IPEX 一代	1

## 深圳市金航标电子有限公司

技术详询

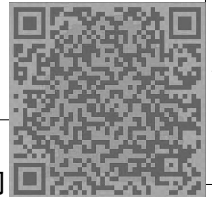

公差	.x	±0.30	变更记录	日期	变更者	料号	编码	
	x.x	±0.20				品名	4G 内置天线	
图法	x.xx	±0.10	比例	纸张	A4	型号	KH-FPC4G-1.13IPEX-100-6417	
	ANGULAR	@5~				绘图	日期	2020.06.30
	单位	MM				版本	A	审核