 


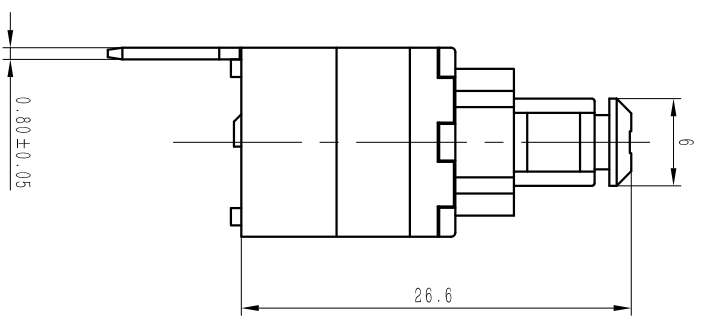


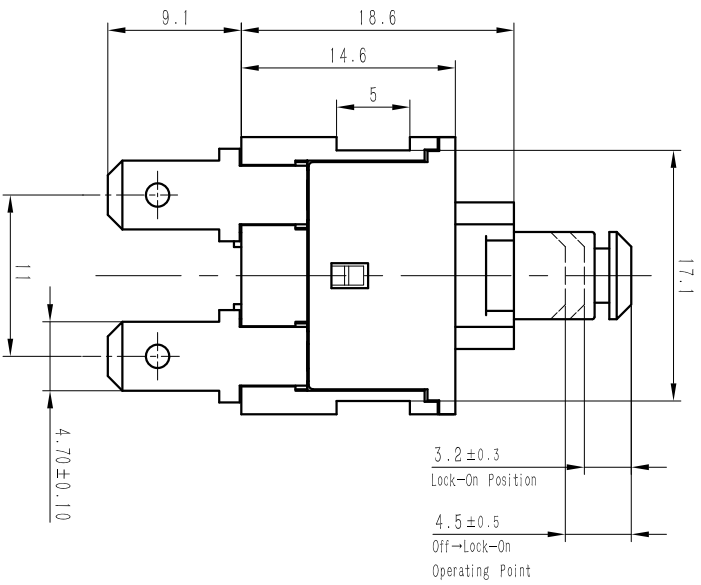

主要技术参数、性能
The Main Technology Performance

 
项目 Item	参数 Parameter
电路图 Circuit	(ON)-OFF带锁  2 ○ ○ 1
操作力 Operating force	1000±500g·f
额定电流、电压 Rated voltage Rated current	见标识图 Marking/Rating
绝缘电阻 Insulated resistance	≥100MΩ
接触电阻 Contact resistance	≤100mΩ
介电强度 Dielectric strength	≥1500V AC/5mA/5s
电气寿命 Endurance	≥50000
使用温度 Ambient temperature	见标识图 Marking/Rating

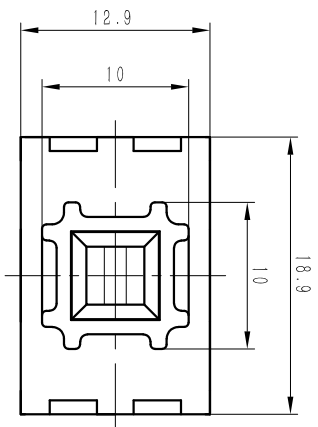

刻字标识:
Marking/Rating:

CNIBAO PAD	CE	16GP(8)A 125V~/250V~	
16(8)A 125V~/250V~ 25T125 SE4		1/2HP 125V~/250V~ 25T125 SE4	

MARK		AMOUNT		MODIFY FILE NO.		CHANGE BY		DATE	
设计 DESIGN		数量		更改文件号		更改人		日期	
审核 CHECK									
批准 APPROVAL									

第三视角 THE THIRD ANGLE PROJECTION		
比例 SCALE	2 : 1	
单位 UNIT	mm	
重量 WEIGHT	一般公差 GENERAL TOLERANCE	
	>0.5~6	±0.10
	>6~30	±0.20
角度 ANGLE	>30~120	±0.30
		±2°

CNIBAO 浙江亿宝 ZHEJIANG YIBAO	按钮开关 PUSH-BUTTON SWITCH
DESIGNATION: PAD-41S-01	