


客户名称 CUSTOMER :


客户料号 CUSTOMER P/N:

产品尺寸 DIAGRAM OF DIMENSIONS:

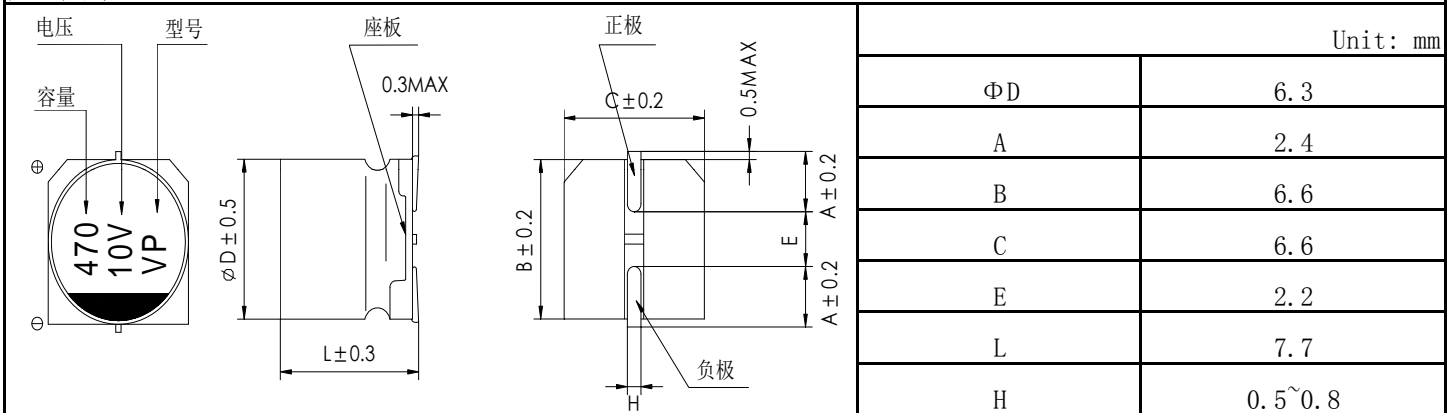

项目 Items	Performance				
温度范围 Operating temperature range	- 55 °C ~ + 105 °C				
容量精度 Capacitance Toleranc	- 20 % + 20 %		(120Hz, 20°C)		
浪涌电压 Surge voltage	13 VDC				
漏电流 Leakage current	I ≤	47	μ A	After 2 minutes	
损耗正切值 Dissipation Factor (Tan δ)	≤ 0.19		(120Hz, 20°C)		
阻抗 E. S. R	≤ 0.16		Ω	(100KHz, 20°C)	
纹波电流 Ripple Currents (rms)	MAX 600		mA	(100KHz, 105°C)	
阻抗比 Low Temperature Characteristics (120Hz)	Z-25°C / Z+20°C		2		
	Z-40°C / Z+20°C		3		
频率修正系数 Ripple Current & Frequency Multipliers	Frequency (Hz)	50HZ	120HZ	50KHZ	≥100KHZ
	Multipliers	0.35	0.65	0.98	1
高温负荷 Load Life Test: After 2000 Hrs at 105°C	Capacitance Change	Within ±30% of initial value			
高温存储 Shelf Life Test: After 1000 Hrs at 105°C	Dissipation Factor	Not more than 200% of the initial specified value			
	Leakage current	The initial specified value or less			
可靠性试验标准 Standards	JIS C 5101-1, -18				
环境物质 Remarks	RoHS Compliance & Halogen-free				

产品标示 Marking: Each capacitor shall be marked with the following information.

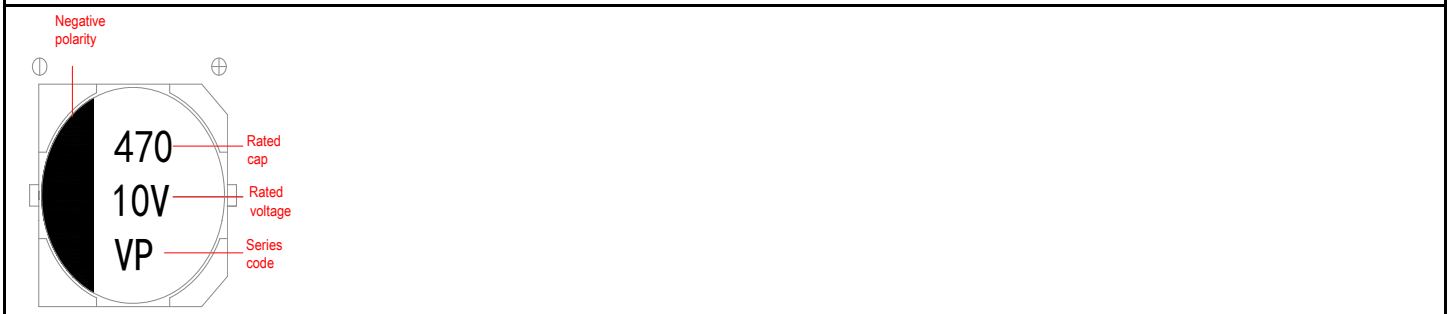

Marking color: Black

Publish Date	2018/5/17	Approval Signatures:	Approved	Checked	Designed
Revise Date			陈进	吴洋洋	吴洋洋
Edition No.		Please return one copy with your approval			