



HSF

NOTES:
 Rated Current: 3.0AMP
 Contact Resistance: 20mΩ Max.
 Withstand Voltage: 1000V AC/DC
 Insulation Resistance: 1000MΩ Min.
 Operation Temperature: -25°C to +85°C

Contact Material: Brass
 Contact plating: Au Or Sn Over Ni
 Insulator Material: PA66/PA46(UL94V-0/2)

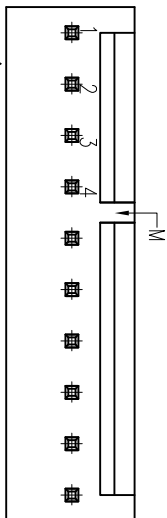

△ <10P: 无掬料槽
 示意图

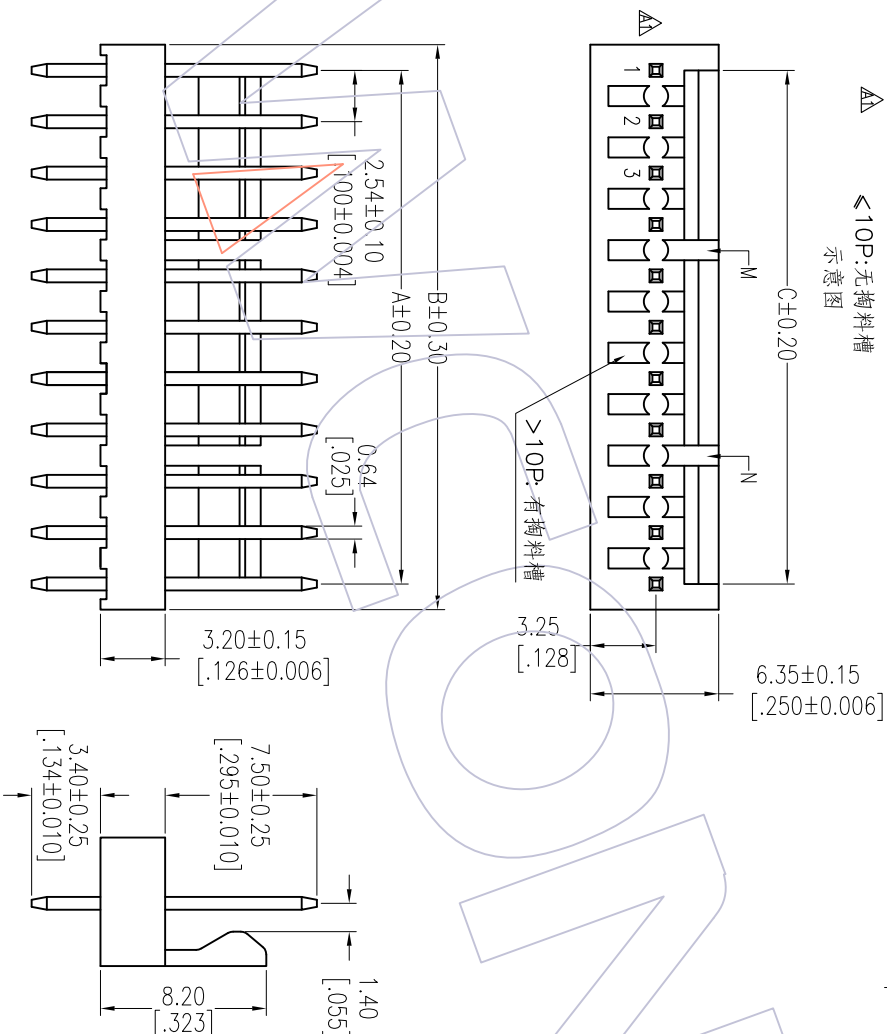

Ordering Information

WF2546-WS XX XX W 0 X

No. of Pins Contact Plating Color Packing
 02-20Pin
 H=PA46
 Blank=PA66


S=Gold Flash/Tin
 SS=10u"Gold/Tin
 S4=15u"Gold/Tin
 SS=30u"Gold/Tin
 G0=Gold Flash
 G3=10u"Gold
 G4=15u"Gold
 G5=30u"Gold
 Blank=Tin

W=White
 O=PE Bag

Circuit	Slot M	Slot N	Dimension			QTY/ bag
			A	B	C	
2~5P	None	None				
6~10P		None				
11~14P	Between Circuit4,5P					Between Circuit8,9P
15~18P	Between Circuit4,5P					Between Circuit12,13P
19~20P	Between Circuit4,5P					Between Circuit16,17P

Dimensional & Ordering Information

Circuit	Part No.	Dimension			QTY/ bag
		A	B	C	
02	WF2546-WS02XXX	2.54	5.08	2.54	1,000
03	WF2546-WS03XXX	5.08	7.62	5.08	1,000
04	WF2546-WS04XXX	7.62	10.16	7.62	1,000
05	WF2546-WS05XXX	10.16	12.70	10.16	500
06	WF2546-WS06XXX	12.70	15.24	12.70	500
07	WF2546-WS07XXX	15.24	17.78	15.24	500
08	WF2546-WS08XXX	17.78	20.32	17.78	500
09	WF2546-WS09XXX	20.32	22.86	20.32	400
10	WF2546-WS10XXX	22.86	25.40	22.86	400
11	WF2546-WS11XXX	25.40	27.94	25.40	300
12	WF2546-WS12XXX	27.94	30.48	27.94	300
13	WF2546-WS13XXX	30.48	33.02	30.48	300
14	WF2546-WS14XXX	33.02	35.56	33.02	300
15	WF2546-WS15XXX	35.56	38.10	35.56	200
16	WF2546-WS16XXX	38.10	40.64	38.10	200
17	WF2546-WS17XXX	40.64	43.18	40.64	200
18	WF2546-WS18XXX	43.18	45.72	43.18	200
19	WF2546-WS19XXX	45.72	48.26	45.72	200
20	WF2546-WS20XXX	48.26	50.80	48.26	200

 

Recommended P.C.B Layout(Top Side)
 (PCB BOARD TOLERANCE±0.05)

REV	DATE	MODIFICATION DESCRIPTION	CHANGE	OPERATION	SCALE	FIT	PART NO.
A1	2014/07/02	Modify The View		XX ±0.40	mm	1/1	SEE TAB
AO	2012/09/08	NEW		XXX ±0.25 XXX ±0.15	A4		"M" TYPE 2.54 WAFER 180°
				Angle ± 3°			Customer NO.

WCON

Http: www.wcon.com

WCON-Dongguan Tel: +86 769 85358920
 WCON-Kunshan Tel: +86 512 57468408
 Fax: +86 769 85358915
 Fax: +86 512 57468468
 E-mail: sales@wcon.com
 E-mail: salesks@wcon.com