
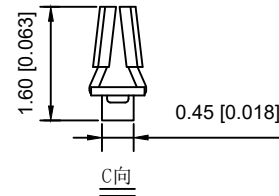


■ Specifications :

- Voltage rating: 50 V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: ≥100MΩ
- Contact resistance: ≤20mΩ
- After environmental testing: ≤40mΩ

X1002 T- P XX-E
① ② ③ ④ ⑤

- ① Series No.
- ② Category : T-terminal
- ③ Material:P-Phosphor bronze
- ④ Plating Style:
V01-All Gold Flash
SN-Bright tin plating 70u";30u" Ni
SN2-50u" Ni Min,120u" Tin Min
- ⑤ Plug the Pin & Special No:E-Have ears

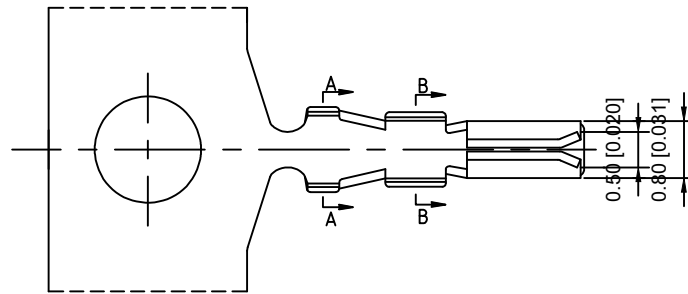

X1002T-PV03-E	Phospho Bronze	AWG#28-32	0.80mm	Stamping Before Plating:30-50u" Ni:Whole Gold .3u" Min	X1002H
X1002T-PV01-E				Stamping Before Plating:30-50u" Ni:Whole Gold Gold Flash	
X1002T-PSN2-E				Stamping Before Plating:50u" Min Ni:120u"Sn Min	
X1002T-PSN-E				Stamping Before Plating:30-50u" Ni:70-120u"Sn	
PART No	Material	Wire Range	Insulation O.D.	Finish	Suitable XKB Terminal

DSND		DATE		SCALE: N/A	MODEL TYPE: X1002T-XXX-E
DWN		DATE		VIEW:	PART NO.: 1.0mm Crimp Style Connectors
CHKD		DATE		UNIT: mm/in	DWG NO.:
APPD		DATE		SIZE: A4	
UNSPECIFIED TOLERANCES				XKB INDUSTRIAL PRECISION CO.,LIMITED	
				WEIGHT	SHEET
				1.0g	1/1
				REVISION	A0