



specification

SHEET FOR APPROVAL

Part Name: _____ electro-magnetic buzzer _____
 Type: _____ YX-KC9042C _____
 Customer Name: _____
 Number of the Edition: _____



	Approved by	Checked by	Issued by
Signature			
Date			

Yue Xin Electronics Co., Ltd.
 Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China
 Tel: +86 0523 83722059 Fax: +86 0523 83722259
 Web: www.xhyxdz.com



Electro-magnetic Buzzer


YXKC9042C

Electrical Characteristics

Model No.	YX-KC9042C		
Rated Voltage(VDC)	1.5	3	5
Operating Voltage (VDC)	1-3	2~4	4~6
*Rated Current (mA)	80	60	60
*Sound Output at 10cm (dB)	80	80	85
Resonant Frequency (Hz)	2731		
Coil Resistance(Ω)	5.5±1	16±3	40±4
Operating Temperature (°C)	-20~+70		
Storage Temperature (°C)	-30~+80		
Weight (g)	1		
Housing Material	PPT		

Appearance Drawing

(UNT: mm) Tolerance: ±0.5mm Except Specified

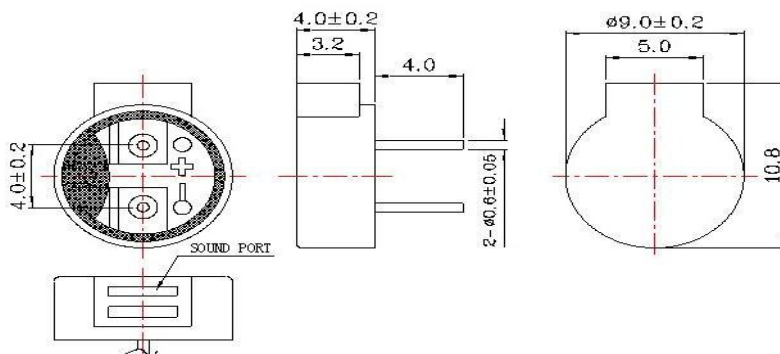

Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259


Web: www.xhyxdz.com




Electro-magnetic Buzzer

YX-KC9042C

Testing Method:

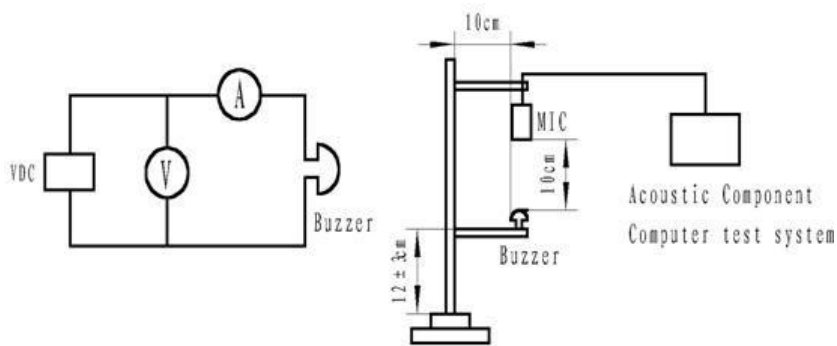

Frequency Response:

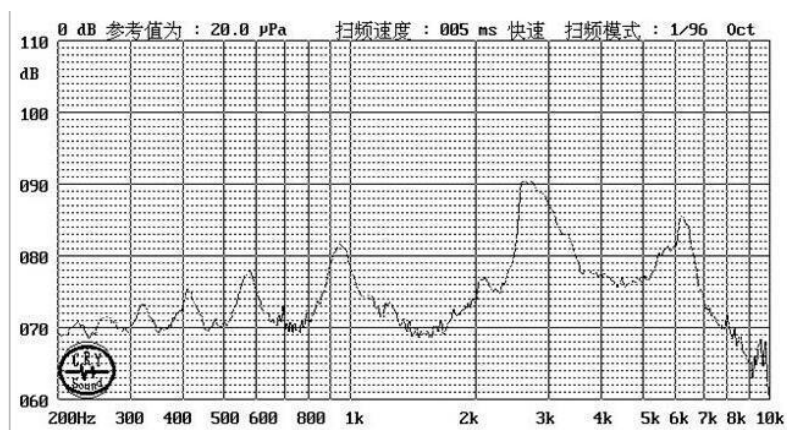

Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 **Fax:** +86 0523 83722259

Web: www.xhyxdz.com