



piezoelectric buzzer

YXYD2319




Electrical Characteristics

Rated Voltage(Square Wave)	V	6	12
Operating Voltage	V	3-9	3-24
*Rated Current(MAX)	mA	13	14
*Min Sound Output at 10 cm	dB	90	
*Resonant Frequency	Hz	3700 ± 500	
Operating Temperature	℃	-20~+60	
Storage Temperature	℃	-30~+70	
Housing Material		ABS	
Weight	g	5	

(UNT: mm)

Tolerance: ±0.5mm Except Specified

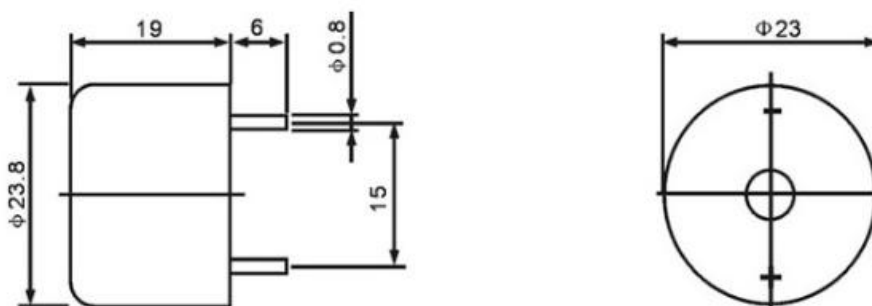

Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Web: www.xhyxdz.com




piezoelectric buzzer


YXYD2319



Testing Method:

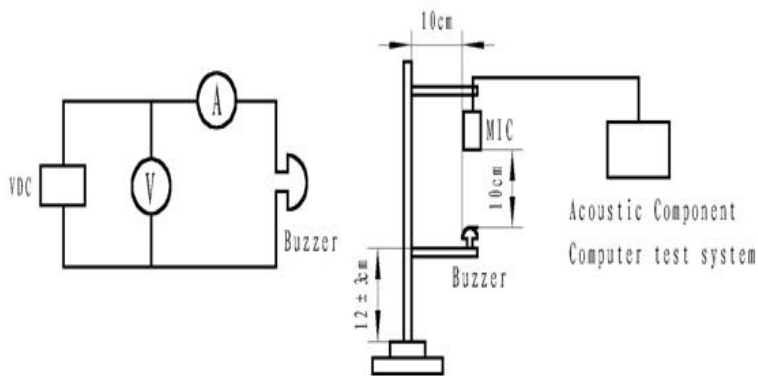

Frequency Response:

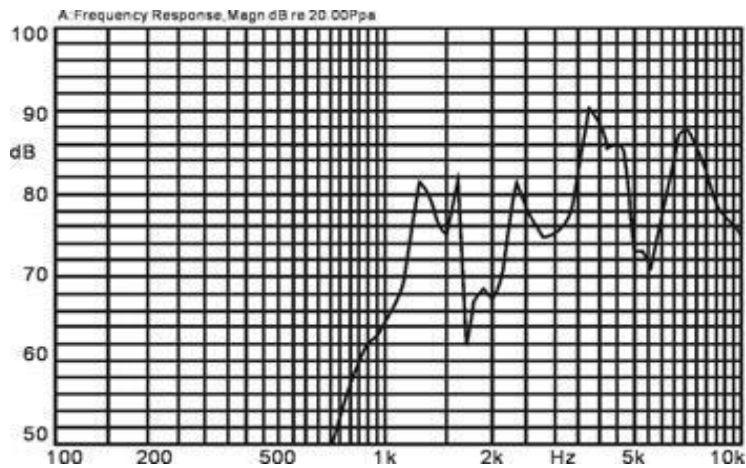

Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Web: www.xhyxdz.com