

**SPECIFICATIONS**

- 1.Voltage rating: 50V AC, DC
- 2.Current rating: 1A, AC, DC
- 3.Withstanding Voltage: 500V AC/minute
- 4.Insulation resistance:100M min
- 5.Temperature range: -25 ° C--+85 ° C
- 6.Contact resistance: 20m max

**HOUSING**

Housing Material:Nylon66 UL94V-0(2)




Accepts :T1010 terminal

Mates with: M1010 series header

Poles : 10-50P

Part No.: P1010-2xXX-N0

Pin位数

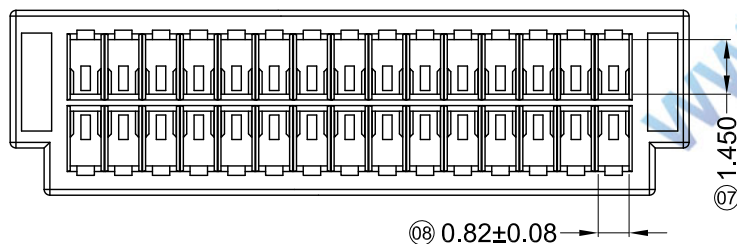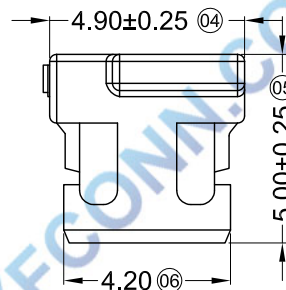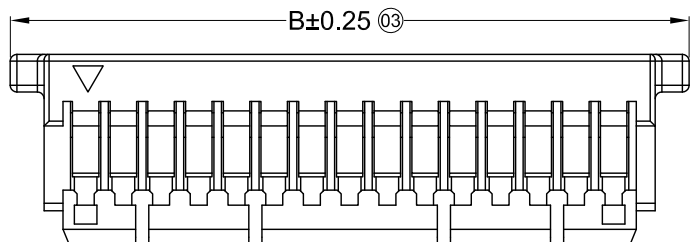

Poles	Dimensions(mm)		Poles	Dimensions(mm)	
	A	B		A	B
10	4.00	8.00	30	14.00	18.00
12	5.00	9.00	40	19.00	23.00
16	7.00	11.00	50	24.00	28.00
20	9.00	13.00			

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	<b>XFCN</b> 兴飞连接器有限公司 CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	1.00mm Crimp Style Connectors	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	P1010-2xXX-N0	
				.XXX	±0.03	.XXX°	±0.5°			UNITS	mm
A0	MODIFICATION			DRAW	DATE				SCALE	1:1	
VER									DWG. NO.	009	