


■ Specifications :

- Voltage rating: 50 V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: ≥500MΩ
- Contact resistance: ≤20mΩ
- After environmental testing: ≤30mΩ

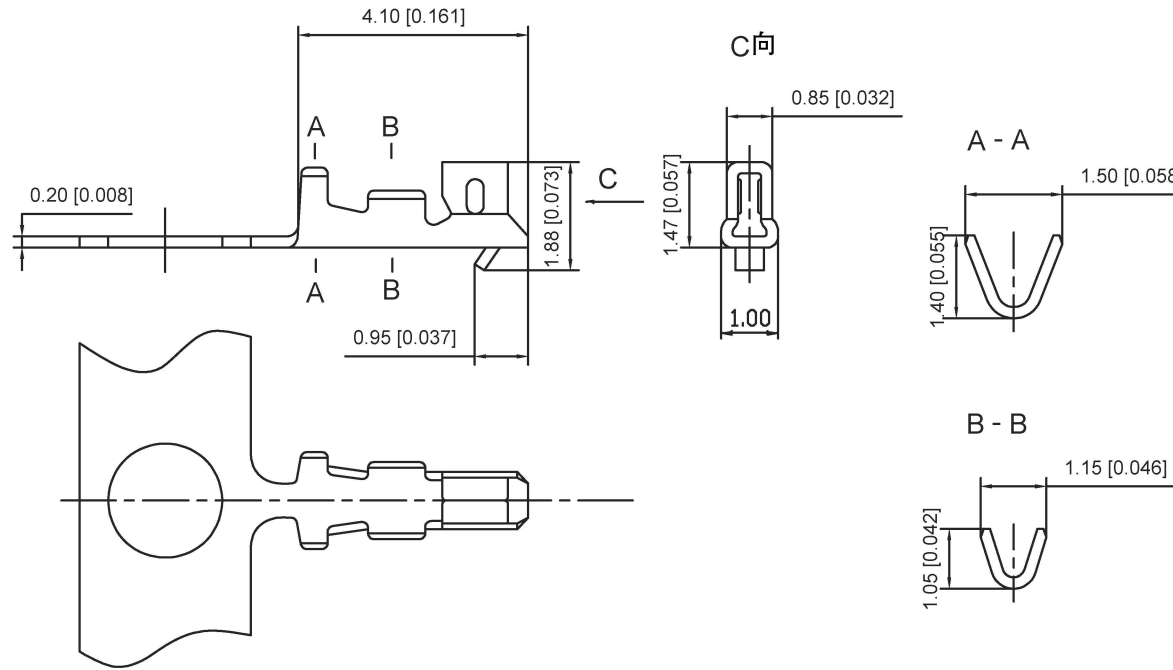

X1502 T-P SN

- ① Series Number
 ② Category : T-terminal
 ③ Material: P-Phosphor bronze
 ④ Plating style: SN-Bright tin plating

X1502T-PSN	Phosphor Bronze	AWG#26-32	1.20mm(Max)	Stamping Before Plating :30u" Ni,70u" Sn	X1502H
PART NO	Material	Wire Range	Insulation O.D.	Finish	Suitable XKB Terminal

广东星坤科技股份有限公司

生效

日期

文件工程章

DSND	DATE	SCALE: N/A	MODEL TYPE: X1502T-PSN
DWN	DATE	VIEW:	PART NO.: 1.5mm Crimp Style Connectors
CHKD	DATE	UNIT: mm/in	DWG NO.:
APPD	DATE	SIZE: A4	
UNSPECIFIED TOLERANCES			WEIGHT
XKB INDUSTRIAL PRECISION CO., LIMITED			SHEET
			REVISION
			1.0g
			1/1
			A0

REVISIONS

DATE REVISED APPROVED

www.xk-dg.cn www.helloxkb.com www.helloxkb.cn