


M 2 : 1

Verpackung Stange / Stange & Ansaughaube
packaging tube / tube&cap

100	9
80	11
70	13
60	15
50	18
40	23
30	31
20	46
10	89
Polzahl No. of positions	Stück / pieces

Masse und Toleranzen in Übereinstimmung mit ANSI Y15.5M-1994 /
Interpret dimensions according to ANSI Y15.5M-1994

109514	109505	109496	109487	100	65.23	62.23
109513	109504	109495	109486	80	52.53	49.53
109512	109503	109494	109485	70	46.18	43.18
109511	109502	109493	109484	60	39.83	36.83
109510	109501	109492	109483	50	33.48	30.48
109509	109500	109491	109482	40	27.13	24.13
109508	109499	109490	109481	30	20.78	17.78
109507	109498	109489	109480	20	14.43	11.43
109506	109497	109488	109479	10	8.08	5.08
Id-Nr. tube&cap 100 mating- cycles	Id-Nr. tube&cap 10 mating- cycles	Id-Nr. tube 100 mating- cycles	Id-Nr. tube 10 mating- cycles	Polzahl no of positions	Mass A	Mass B

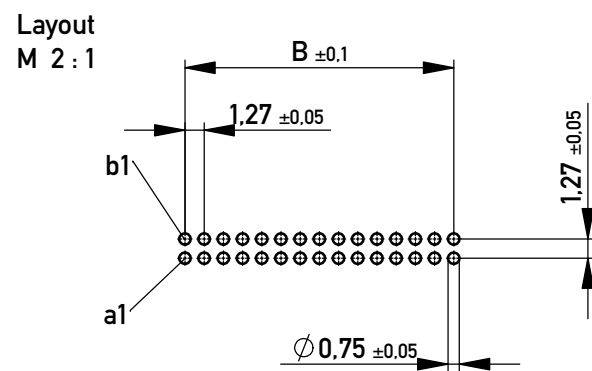

Copyright by ERNI GmbH
Proprietary notice pursuant to ISO 16016 to be observed.

Information:	Tolerances	All Dimensions in mm	Scale 5:1
All rights reserved. Only for Information. To ensure that this is the latest version of this drawing, please contact one of the ERNI companies before using.	Subject to modification without prior notice. Drawing will not be updated.	Designation	
		MiniMez Vertical Female DIP w/o pegs 4,6mm	
	www.ERNI.com	109478	
Index	Date	Class	MINIMEZ
			I A3