

Kinghelm[®]

KINGHELM Satellite receiving antenna

GPS Active Antenna

kinghelm-KH1GBC01-A/2(3M)




SHENZHEN KINGHELM ELECTRONIC CO., LTD

Add: Floor 2, building 4, Baoshan youpin cultural creative park, minfu road, minzhi street, Longhua new district District:

[Http://www.kinghelm.cn/](http://www.kinghelm.cn/)

Tel: 86-755-83247607

Fax: 86-755-83975897

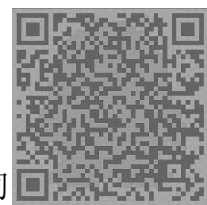


技术详询



KINGHELM Satellite receiving antenna

外型尺寸:

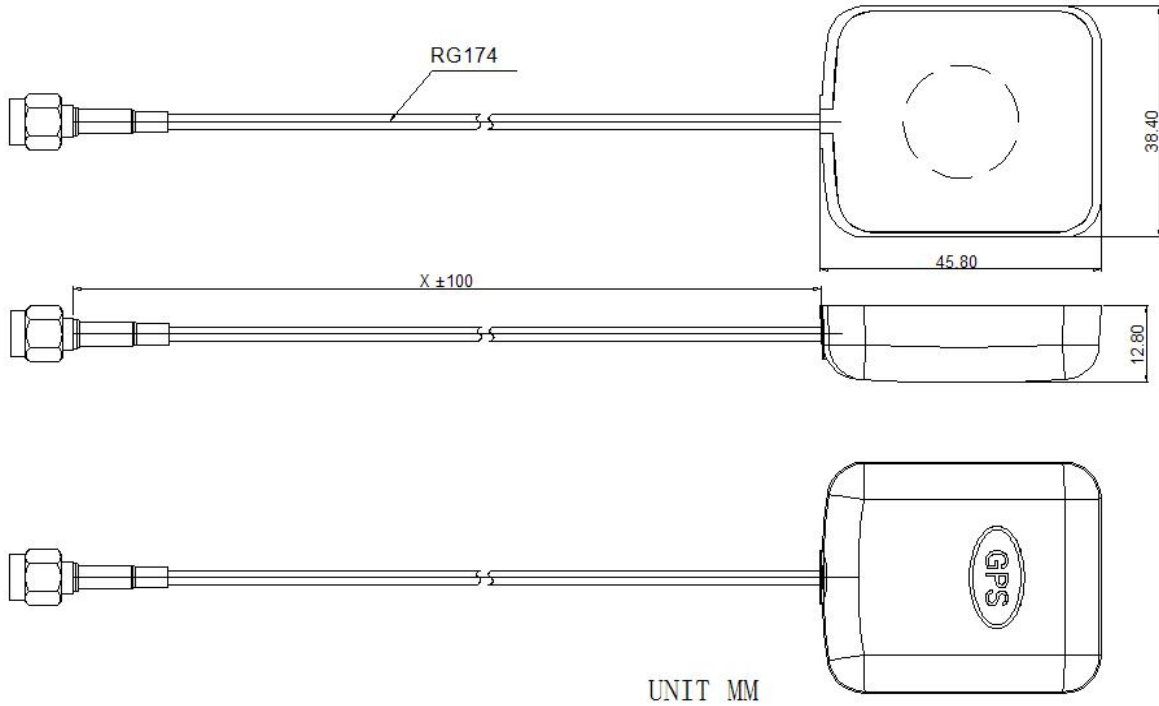

X=3M

SHENZHEN KINGHELM ELECTRONIC CO., LTD

Add: Floor 2, building 4, Baoshan youpin cultural creative park, minfu road, minzhi street, Longhua new district District:

[Http://www.kinghelm.cn/](http://www.kinghelm.cn/)

Tel: 86-755-83247607

Fax: 86-755-83975897



KINGHELM Satellite receiving antenna

规格参数:

Item	Specifications	
Antenna	Center Frequency	1575.42 ± 10MHz
	Band Width	CF ± 5MHz
	Polarization	RHCP
	Gain	2dBic (Zenith)
	V.S.W.R	<1.3
	Impedance	50 Ω
	Axial Ratio	3dB (max)
	Dimension	45.8*38.4*12.8mm
LNA	Gain	29 ± 2dB
	Noise Figure	<1.3
	Supply Voltage	1.4~3.6V DC
	Current Consumption	8~15mA
	V.S.W.R	<2.0
Mechanical	Cable	RG174
	Connector	SMA-J
	Radome Material	ABS
	Mounting Method	Magnet/Adhesive
Environmental	Operating Temperature	-40°C~+85°C


SHENZHEN KINGHELM ELECTRONIC CO., LTD

Add: Floor 2, building 4, Baoshan youpin cultural creative park, minfu road, minzhi street, Longhua new district District:

[Http://www.kinghelm.cn/](http://www.kinghelm.cn/)




Tel: 86-755-83247607

Fax: 86-755-83975897

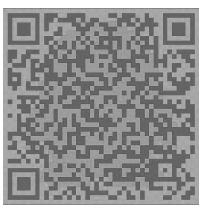


技术详询


测试效果图:

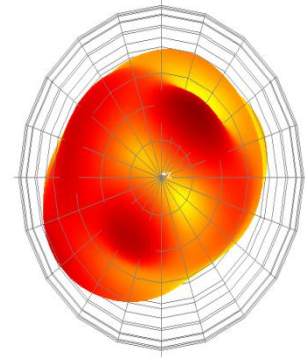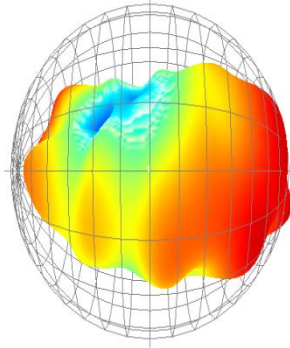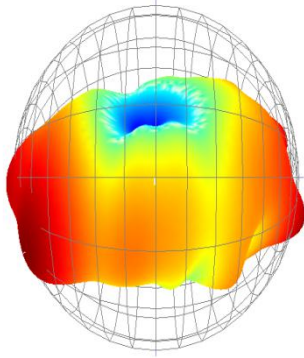


X+

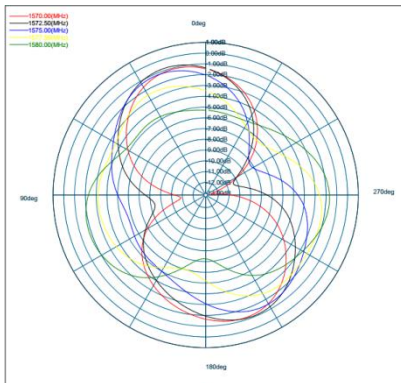

Y+

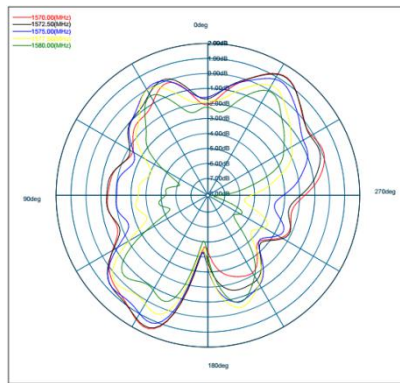

Z+

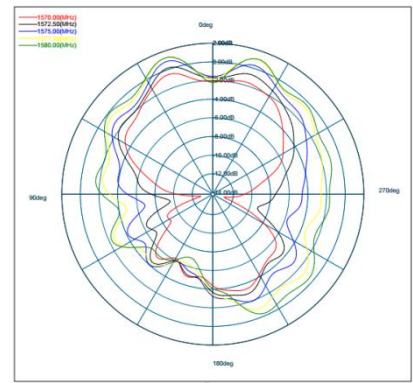

XY

YZ

XZ

SHENZHEN KINGHELM ELECTRONIC CO., LTD

Add: Floor 2, building 4, Baoshan youpin cultural creative park, minfu road, minzhi street, Longhua new district District:

[Http://www.kinghelm.cn/](http://www.kinghelm.cn/)

Tel: 86-755-83247607

Fax: 86-755-83975897

技术详询

