


环保物料



TEL:0769-82001899

**SPECIFICATIONS**



- 1.Voltage rating: 250V AC, DC
  - 2.Current rating: 5A, AC, DC
  - 3.Withstanding Voltage: 1500V AC/minute
  - 4.Insulation resistance:1000M min
  - 5.Temperature range: -25 ° C-+85 ° C
  - 6.Contact resistance: 10m max
- HOUSING**  
 Housing Material:Nylon66 UL94V-0(2)  
 Accepts :T3025 terminal  
 Mates with: M3025 series header  
 Poles : 02-12P  
 Part No.: P3025-1xXX-BK

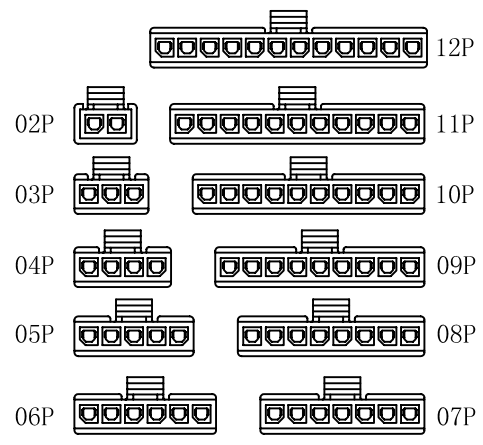


CIRCUIT SIZE LAYOUT

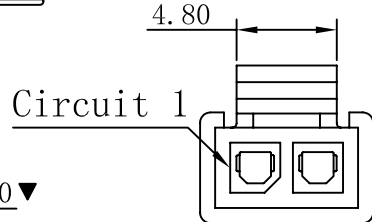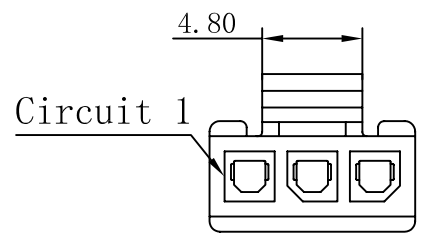

Pin位数

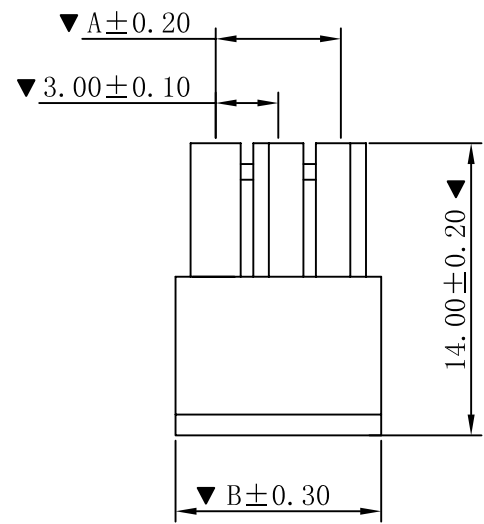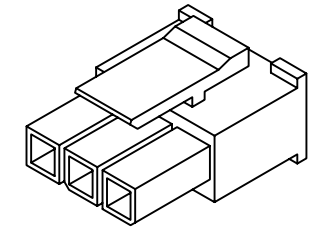

3P-12P

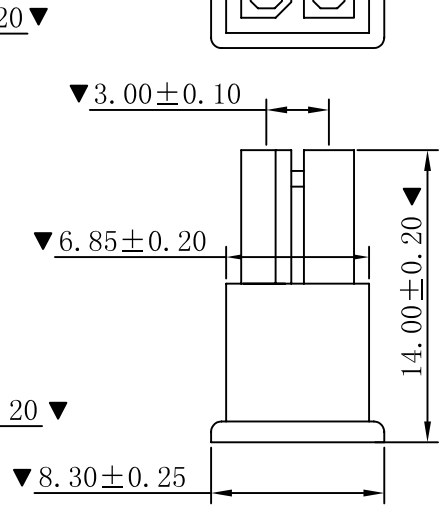

2P

Part No	Dimensions (mm)	
	A	B
02	3.00	6.85
03	6.00	9.85
04	9.00	12.85
05	12.00	15.85
06	15.00	18.85
07	18.00	21.85
08	21.00	24.85
09	24.00	27.85
10	27.00	30.85
11	30.00	33.85
12	33.00	36.85

TOLERANCE UNLESS OTHERWISE

X.	$\pm 0.30$	X°	$\pm 5^\circ$
.X	$\pm 0.20$	.X°	$\pm 2^\circ$
.XX	$\pm 0.08$	.XX°	$\pm 1^\circ$
.XXX	$\pm 0.03$	.XXX°	$\pm 0.5^\circ$

DRAWN CK tan

CHKD
APPD
VIEW

**XFCN** 兴飞连接器有限公司  
 XFCN CONNECTORS CO.,LTD.

PRODUCT NAME	3.00mm Crimp Style Connectors
PART. NO.	P3025-1xXX-BK

SHEET 1/1

DATE 2020.04.12

UNITS mm

SCALE 1:1

DWG NO. 009

AO

VER

MODIFICATION

DRAW

DATE

1 2 3 4 5 6 7 8 9 10