

Technical Data





Material:
 Contact Material: Brass
 Contact plating: Au or Sn Over 50μ" Ni
 Insulator Material: Black Polyester UL94V-0
 Standard: PA6T/PA9T/LCP+30%G.F

Electrical:
 Current rating: 1.0Amps/contact max.
 Contact resistance: ≤20mΩ/contact
 Insulation resistance: ≥500MΩ at V=100V
 Withstanding Voltage: 500V AC/minute

Mechanical:
 Mechanical life cycle: min.200
 Operating temperature: -40°C to +105°C
 Soldering temperature: +255°C

包装方式: 袋装

Dimension antitheses list (尺寸选型表)					
Item (项目)	L	PA	PC	H	W1
Standard (尺寸)	7.4	2.0	2.9	2.5	2.5
Remarks (备注)	以上尺寸可由客户选择				

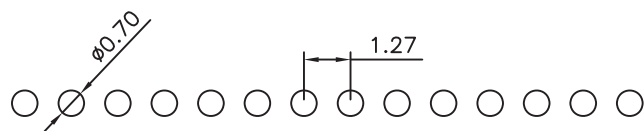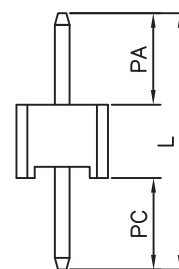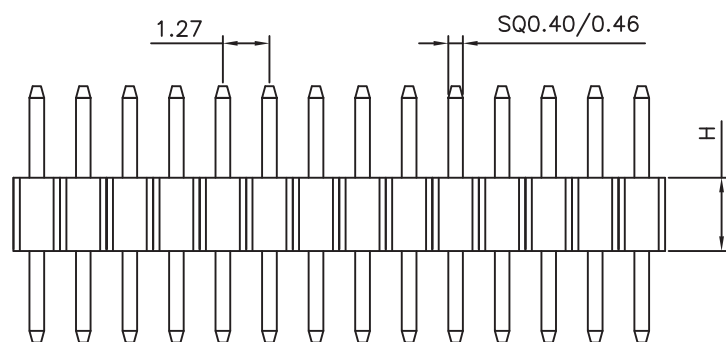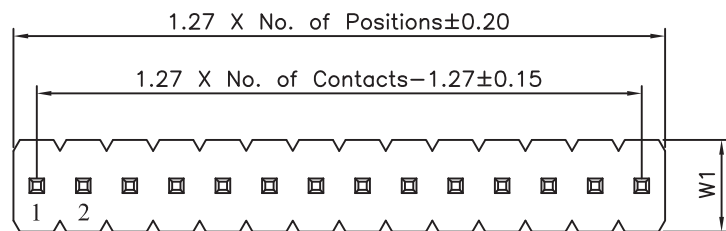

P.C.B LAYOUT

				TOLERANCE UNLESS OTHERWISE	DRAWN	CK tan	XFCN 兴飞连接器有限公司 XFCN CONNECTORS CO.,LTD.	SHEET	1/1	
				X. ±0.30 X° ±5°	CHKD			DATE	2020.04.12	
				.X ±0.20 .X° ±2°	APPD	PRODUCT NAME		1.27mm Pin Header Connectors	UNITS	mm
				.XX ±0.08 .XX° ±1°	VIEW	PART. NO.		PZ127V-11-xx-H25	SCALE	1:1
AO	MODIFICATION	DRAW	DATE	.XXX ±0.03 .XXX° ±0.5°				DWG NO.	009	