


## HJ-9059-1880-1930MHz

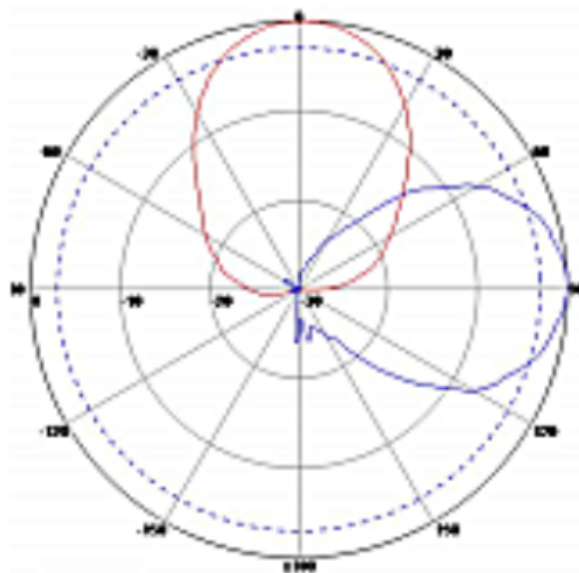

### ELECTRICAL :

- Frequency Range : 1880-1930MHz
- Impedance : 50Ω
- V.S.W.R. :  $\leq 2.0$
- Gain :10.0dBi
- Efficiency(%): >65%

### MECHANICAL :

- Color : Black
  - Operating Temperature : -20°C ~ +65°C
  - Storage Temperature : -30°C ~ +75°C
  - Connector : SMA 公头母针
  - Cable L : 2m (Black)
- Part Number : HJ-9059