


CUT-OUT

Nut Torque:5~14Nm
 Operating Pressure:500gf ±100gf
 Operating Stroke:0.5mm±0.1
 Protection Grade:IP67
 Function:(ON)-OFF
 Shell:Aluminum alloy anodizing black
 Button:Aluminum alloy anodizing black
 Lamp Type:LED
 Lamp Life:50000H
 Rating: 50mA 12V DC
 Contact Resistance: 50mΩ MAX.
 Insulation Resistance: 100MΩ MIN.
 Dielectric Strength: 1500VAC 1 minute
 Electrical life: 50,000 cycles
 Mechanical life :200,000 cycles
 Operating Temperature: -20°C~80°C
 Relative Air Humidity:45%~85%
 Safety Approval:

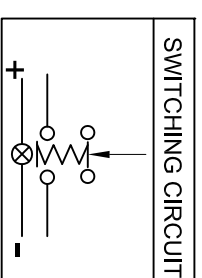

公差 TOLERANCES .X±0.5 .XX±0.3 角度 ANGLE ±1° 单位 DIMENSION UNIT mm.

版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECN NO.	批准 APPROVED BY	核对 CHECKED BY	绘图 DRAWN BY	品名 TITLE	图号 DRAWING NO
				版本 VERSION	比例尺 SCALE	日期 DATE		
				A0	1:1	2020.06.10		
						孙成	PBM-12Q12-FB-W4-R12-A6S-B1	PBM-12Q12-FB-W4-R12-A6S-B1-A0