


Nut Torque: 5 ~ 14Nm
 Operating Pressure: 500gf ±200gf
 Operating Stroke: 1.9mm ±0.5mm
 Protection Grade: IP65 IK08
 Function: (ON)-OFF
 Contact: Silver Alloy
 Base: PBT
 Shell: Brass, Ni Plating
 Button: SUS
 Terminal: Brass, silver
 Lamp Type: LED
 Lamp Life: 50000H
 Rating (Resistive load): 3A 250V AC
 Contact Resistance: 50mΩ Max
 Insulation Resistance: 100MΩ Min
 Dielectric Strength: 1500V AC 1 minute
 Electrical life: 50,000 cycles
 Mechanical life: 200,000 cycles
 Operating Temperature: -20°C~80°C
 Relative Air Humidity: 45%~85%
 Safety Approval:

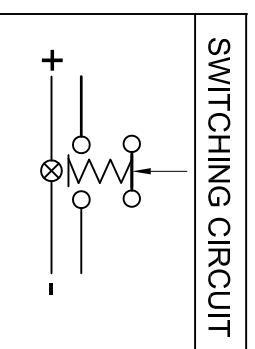

公差 TOLERANCES	.X±0.5	.XX±0.3	角度 ANGLE	±1°	单位	DIMENSION UNIT	mm.
版本 VERSION	A0	比例尺 SCALE	1:1	日期 DATE	2021.04.27	品名 TITLE	图号 DRAWING NO
核准 APPROVED BY		核对 CHECKED BY		绘图 DRAWN BY	孙成	PBM-16M12-FT-G1-R6-B8S-A3	PBM-16M12-FT-G1-R6-B8S-A3_A0
变更说明 CHANGE DESCRIPTION		日期 DATE		ECN NO.			
版本 VER							