
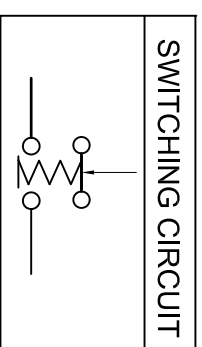


▲注：按键帽子阳极颜色可能存在色差。
XHS-2Y端子具体尺寸参照表格

Nut Torque: 5 ~ 14Nm
 Operating Pressure: 300gf ±100gf
 Operating Stroke: 0.6mm±0.3mm
 Protection Grade: IP67, IK08
 Function: (ON)-OFF
 Contact: Silver Alloy
 Base: PA66
 Shell: SUS

Button: Aluminum alloy anodizing
 Rating: 50mA 48V DC
 Contact Resistance: 50mΩ MAX.
 Insulation Resistance: 100MΩ MIN.
 Dielectric Strength: 1500VAC 1 minute
 Electrical life: 50,000 cycles
 Mechanical life: 200,000 cycles
 Operating Temperature: -20°C~80°C
 Relative Air Humidity: 45%~85%
 Safety Approval:

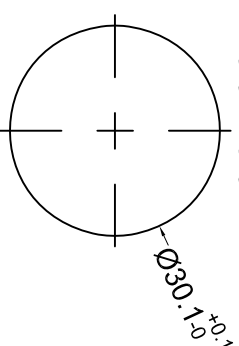

公差 TOLERANCES		.X±0.5 .XX±0.3		角度 ANGLE ±1°		单位		DIMENSION UNIT		mm.	
版本 VERSION	A0	比例尺 SCALE	1:1	日期 DATE	2021.04.27	品名 TITLE		图号 DRAWING NO			
核准 APPROVED BY		核对 CHECKED BY		绘图 DRAWN BY	孙成	PBM-30Q11-FR-N-MN-S/S-A3-Y(Y)(XHS-2Y)		PBM-30Q11-FR-N-MN-S/S-A3-Y(Y)(XHS-2Y)_A0			
版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECN NO.								