



FEATURES

- Kinds of structure and colour for fixed-stand and cover.
- Can choose any colour LED.
- Assemble ways:DIP andSMD.
- Button and tact type,feeling and rhythm are perfect.
- Button have Spray-paint,Plate、Lettering、Enchase。
- Can design the outer assembling structure parts according to customer"s requirements



IMPORT PURPOSE

This product volume small, it is mainly used for digital camera camera, recorder, industrial equipment, household appliances, communications and consumer lights, medical machinery, mobile phone/TV /radio, VCD, DVD, instrument, high-end toys, remote control, small appliances, communication products and computer peripheral products, has extensive USES, production technology is mature, is very stable performance, very competitive advantage.

SPECIFICATIONS

Environment temperature: $-25^{\circ}\text{C}\sim+85^{\circ}\text{C}$

Relative Humidity: $(40^{\circ}\text{C})\leq 80\%$

Rating:DC12V. 50mA

Contact Resistance $\leq 100\text{m}\Omega$

Insulation Resistance: $\geq 100\text{M}\Omega$ DC250V/1Min


Dielectric Strength : AC250V(50Hz for 1minute)

Electrically Life:100,000Cycles

Travel: $0.25\pm 0.1\text{mm}$

Operating Force: $160\pm 50\text{gf}$

Mechanical Life:100,000Cycles

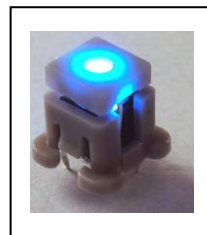


Dimensions are shown: mm
Specifications and dimensions subject to change




LED SPECIFICATIONS

Color	V _R	I _F	Recommended Operating Current	V _F	
				Nom.	Max.
Red	DC 5V	20 mA	20 mA	1.7 V	2.3 V
Green	DC 5V	20 mA	20 mA	1.9 V	2.5 V
Yellow	DC 5V	20 mA	20 mA	1.9 V	2.5 V
Blue	DC 5V	20 mA	20 mA	3.0 V	3.6 V
White	DC 5V	20 mA	20 mA	3.0 V	3.6 V

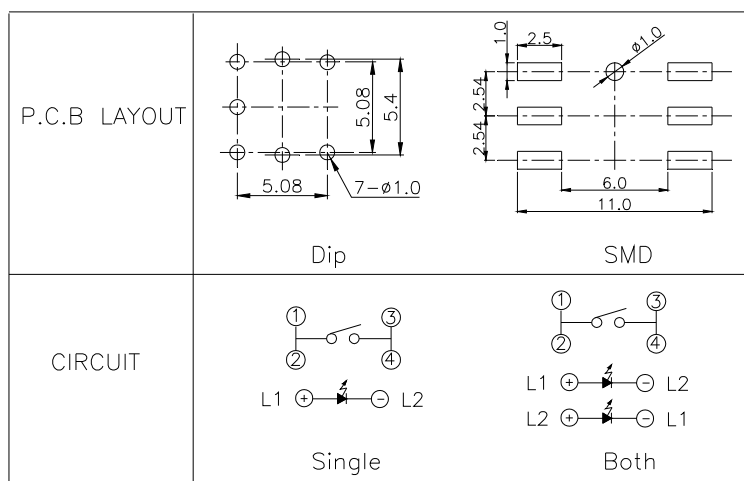

PART NUMBERING SYSTEM

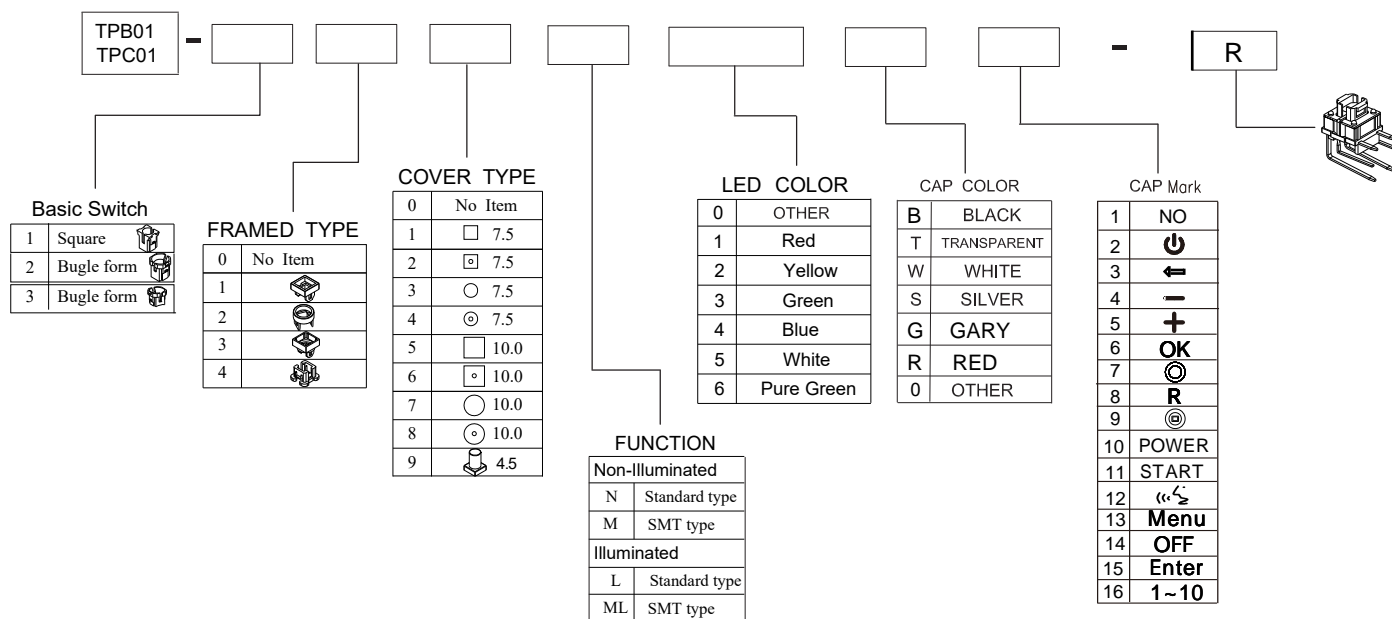

Dimensions are shown: mm
Specifications and dimensions subject to change



<p>TPC01-100N</p>		<p>TPC01-100LX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green																
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		
<p>TPC01-200N</p>		<p>TPC01-200LX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green																
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		
<p>TPC01-100MLX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPC01-200MLX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		
<p>TPC01-300LX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPC01-300MLX</p>	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		
LED COLOR																																			
0	OTHER																																		
1	Red																																		
2	Yellow																																		
3	Green																																		
4	Blue																																		
5	White																																		
6	Pure Green																																		




Third Angle Projection
Dimensions are shown: mm
Specifications and dimensions subject to change





TPB01-101LXXX

Note :

	CAP	
	Mark	Color
2		SILVER BLACK
3		SILVER
6	OK	SILVER
13	Menu	SILVER
14	OFF	SILVER
15	Enter	SILVER
16	1~10	SILVER



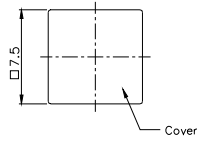


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

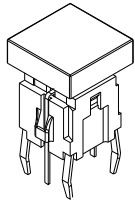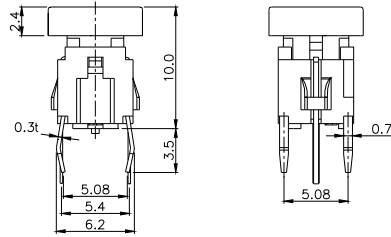

TPB01-102LXX


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

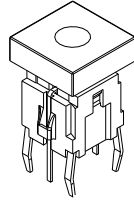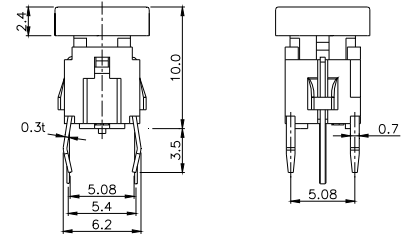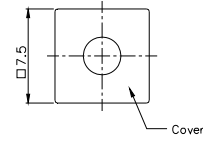



TPB01-103LXXX

Note :

	CAP	
	Mark	Color
2		SILVER BLACK
3		SILVER
4		SILVER
5		SILVER
6	OK	SILVER
7		BLACK
8	R	BLACK
9		SILVER



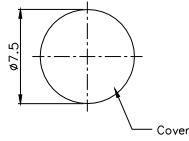


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

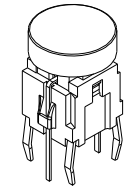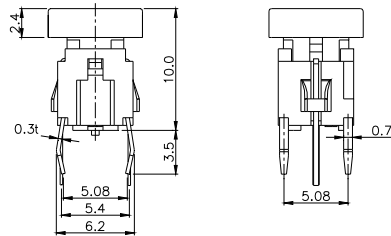




TPB01-104LXX

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

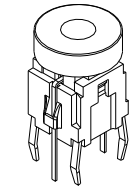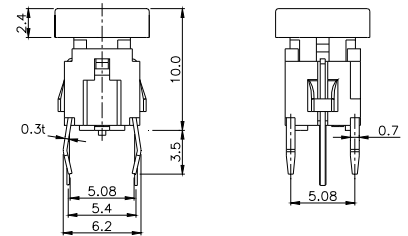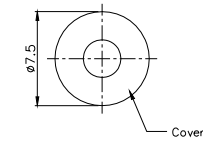




TPB01-105LXX

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

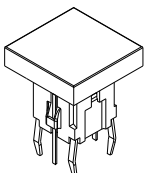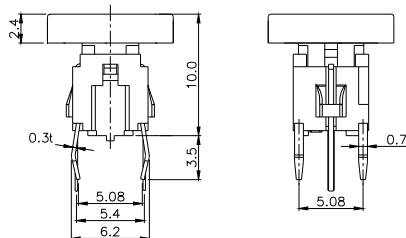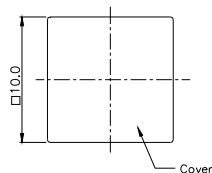

TPB01-106LXX

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

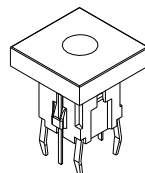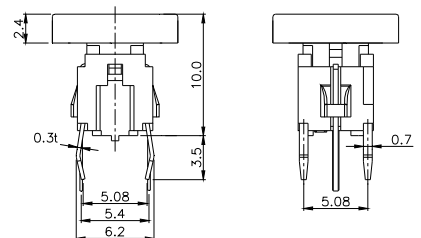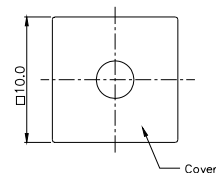



Third Angle
Projection
Dimensions are shown: mm
Specifications and dimensions subject to change




TPB01-107LXXX

Note :

	CAP	
	Mark	Color
2		SILVER BLACK
3		SILVER
4		SILVER
5		SILVER
6		SILVER
7		BLACK
8		BLACK
9		SILVER

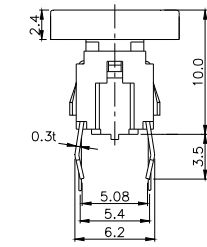
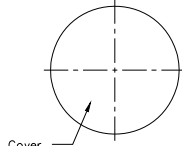


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

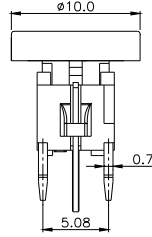


TPB01-108LXXX



	CAP	
	Mark	Color
2		SILVER BLACK
7		SILVER
10		SILVER
11		SILVER
12		SILVER

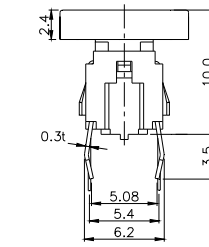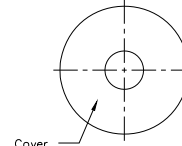


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

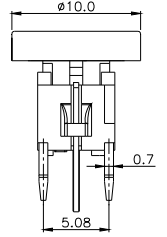



TPB01-109LXX

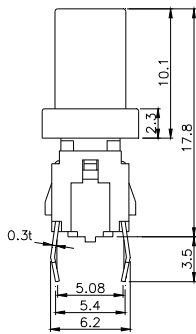 


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

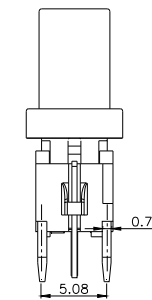

TPB01-1010LXX

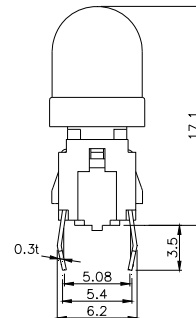 



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

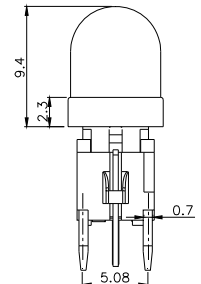


TPB01-1011LXXX

Note :



	CAP	
	Mark	Color
S1		SILVER
S2		BLACK

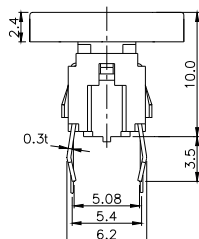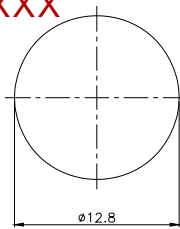


LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

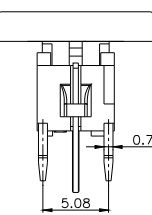

TPB01-1017LXX

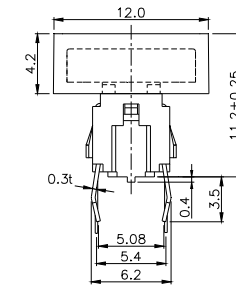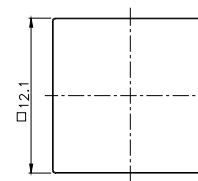

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

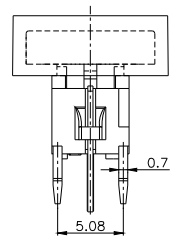

Third Angle
Projection
Dimensions are shown: mm
Specifications and dimensions subject to change



<h3>TPB01-111LXXX</h3> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB01-112LXX</h3> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																							
Mark	Color																																						
2	SILVER BLACK																																						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
<h3>TPB01-123LXXX</h3> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB01-124LXX</h3> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																							
Mark	Color																																						
2	SILVER BLACK																																						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
<h3>TPB01-155LXX</h3> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB01-156LXX</h3> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR																																							
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						



Third Angle Projection
Dimensions are shown: mm
Specifications and dimensions subject to change




<p>TPB01-137LXXX</p> <p>Note:</p> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER</td> </tr> <tr> <td></td> <td>BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER		BLACK	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPB01-138LXX</p> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																									
Mark	Color																																								
2	SILVER																																								
	BLACK																																								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								
<p>TPB01-140LXX</p> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPB01-141LXX</p> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								
<p>TPB01-142LXX</p> <table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<table border="1"> <thead> <tr> <th colspan="2">LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								
LED COLOR																																									
0	OTHER																																								
1	Red																																								
2	Yellow																																								
3	Green																																								
4	Blue																																								
5	White																																								
6	Pure Green																																								





Dimensions are shown: mm
Specifications and dimensions subject to change




TPB01-3012LXX

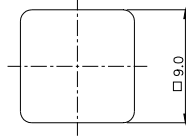



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

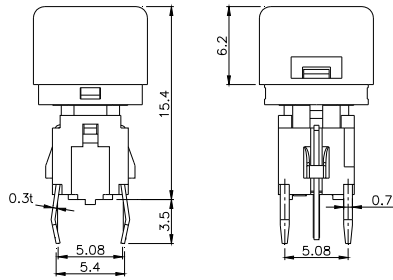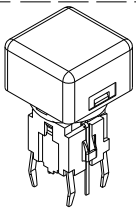


TPB01-3013LXX

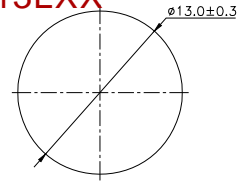



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

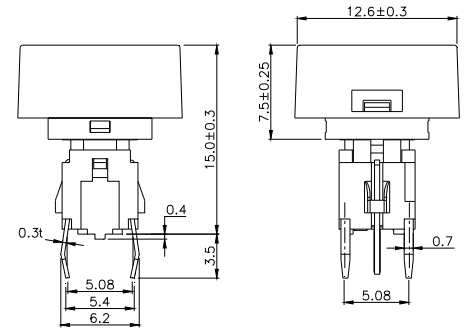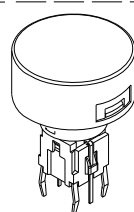


TPB01-3014LXX

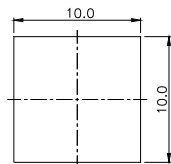



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

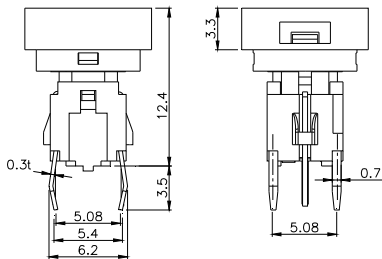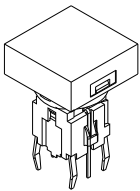


TPB01-3015LXX

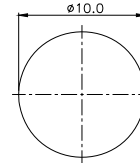



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

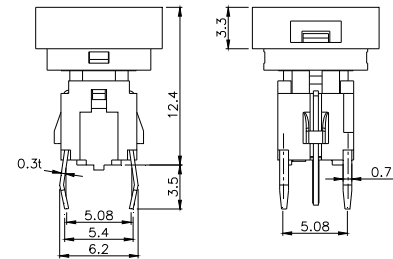 


TPB01-3016LXX

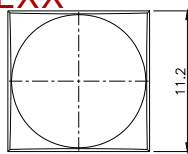



LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

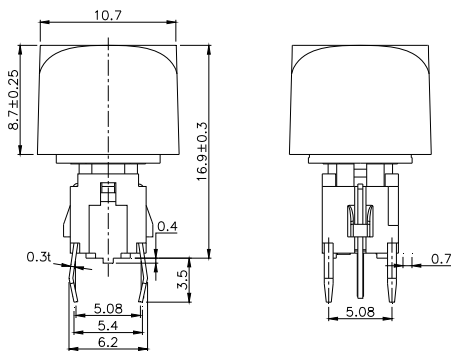 

TPB01-1018LXX

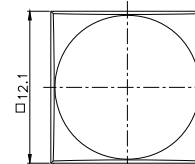

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

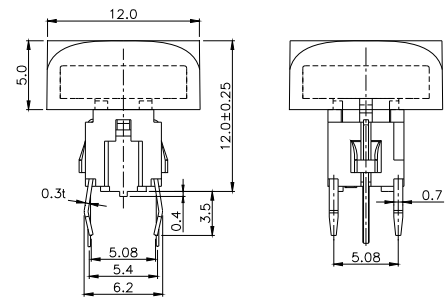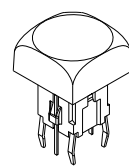


Third Angle
Projection




Dimensions are shown: mm
Specifications and dimensions subject to change



 
TPC01 - 100LX






LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

 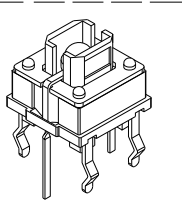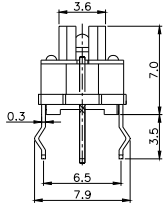


TPC01 - 200MLX

 




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

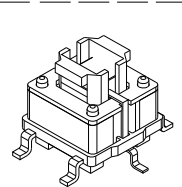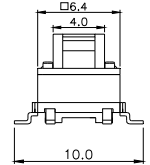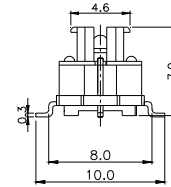


TPC02 - 200LX

 




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

 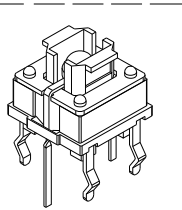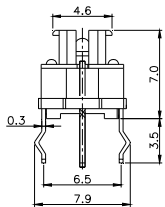


TPC02 - 300ML

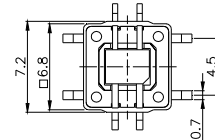




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

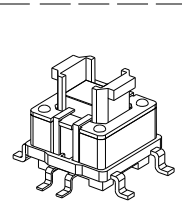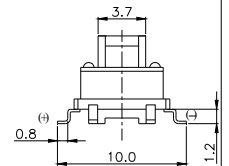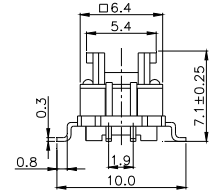


TPC02 - 300LX

 




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

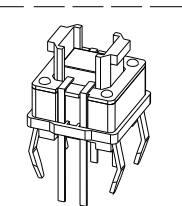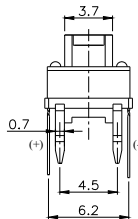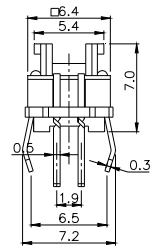


TPC02 - 200LX - R

 




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

 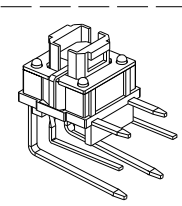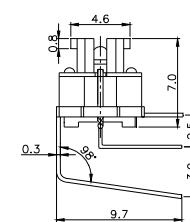


TPB02 - 201LXX

 




LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

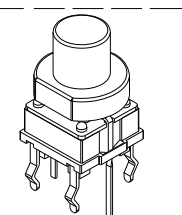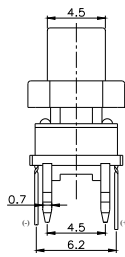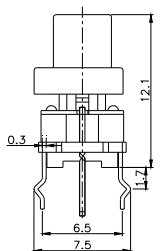

TPC02 - 209LXX - R

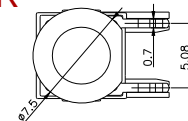

LED COLOR	
0	OTHER
1	Red
2	Yellow
3	Green
4	Blue
5	White
6	Pure Green

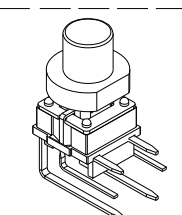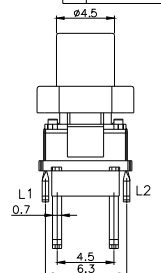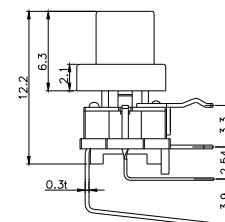

Third Angle
Projection

Dimensions are shown: mm
Specifications and dimensions subject to change



<h3>TPB02-201LXX-R</h3> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB02-202LXX-R</h3> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																							
Mark	Color																																						
2	SILVER BLACK																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
<h3>TPB02-203LXX-R</h3> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB02-204LXX-R</h3> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
<h3>TPB02-205LXX-R</h3> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB02-206LXX-R</h3> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																							
Mark	Color																																						
2	SILVER BLACK																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
<h3>TPB02-207LXX-R</h3> <table border="1"> <thead> <tr> <th colspan="2">CAP</th> </tr> <tr> <th>Mark</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>2</td> <td>SILVER BLACK</td> </tr> </tbody> </table> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<h3>TPB02-208LXX-R</h3> <table border="1"> <thead> <tr> <th>LED COLOR</th> <th>LED COLOR</th> </tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR	LED COLOR	0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
CAP																																							
Mark	Color																																						
2	SILVER BLACK																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						
LED COLOR	LED COLOR																																						
0	OTHER																																						
1	Red																																						
2	Yellow																																						
3	Green																																						
4	Blue																																						
5	White																																						
6	Pure Green																																						



Dimensions are shown: mm
Specifications and dimensions subject to change



<p>TPC03-100LX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPC03-100MLX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
<p>TPB03-101LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPB03-102LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
<p>TPB03-103LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPB03-104LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
<p>TPB03-105LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green	<p>TPB03-106LXX</p> <table border="1"> <thead> <tr><th colspan="2">LED COLOR</th></tr> </thead> <tbody> <tr><td>0</td><td>OTHER</td></tr> <tr><td>1</td><td>Red</td></tr> <tr><td>2</td><td>Yellow</td></tr> <tr><td>3</td><td>Green</td></tr> <tr><td>4</td><td>Blue</td></tr> <tr><td>5</td><td>White</td></tr> <tr><td>6</td><td>Pure Green</td></tr> </tbody> </table>	LED COLOR		0	OTHER	1	Red	2	Yellow	3	Green	4	Blue	5	White	6	Pure Green
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																
LED COLOR																																	
0	OTHER																																
1	Red																																
2	Yellow																																
3	Green																																
4	Blue																																
5	White																																
6	Pure Green																																



Third Angle
Projection

Dimensions are shown: mm
Specifications and dimensions subject to change



<h3>TPB03-107LXX</h3> <table border="1"> <tr><th colspan="2">CAP</th></tr> <tr><td>Mark</td><td>Color</td></tr> <tr><td>2</td><td>SILVER BLACK</td></tr> </table> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	CAP		Mark	Color	2	SILVER BLACK	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green	<h3>TPB03-108LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green
CAP																							
Mark	Color																						
2	SILVER BLACK																						
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
<h3>TPB03-109LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green	<h3>TPB03-1010LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green						
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
<h3>TPC03-111LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green	<h3>TPB03-112LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green						
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
<h3>TPB03-123LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green	<h3>TPB03-124LXX</h3> <table border="1"> <tr><th>LED COLOR</th></tr> <tr><td>0 OTHER</td></tr> <tr><td>1 Red</td></tr> <tr><td>2 Yellow</td></tr> <tr><td>3 Green</td></tr> <tr><td>4 Blue</td></tr> <tr><td>5 White</td></tr> <tr><td>6 Pure Green</td></tr> </table>	LED COLOR	0 OTHER	1 Red	2 Yellow	3 Green	4 Blue	5 White	6 Pure Green						
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							
LED COLOR																							
0 OTHER																							
1 Red																							
2 Yellow																							
3 Green																							
4 Blue																							
5 White																							
6 Pure Green																							



Dimensions are shown: mm
Specifications and dimensions subject to change