

**COIL:**


RESISTANCE 700  $\Omega$   $\pm$  10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.5 VDC  
 MUST RELEASE 1.5 VDC

**ENVIRONMENT:**

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 5 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C


NOTES: DIELECTRIC - 1000 VRMS EXCEPT  
500 VRMS ACROSS OPEN CONTACTS.

**CUSTOMER DATA SHEET**

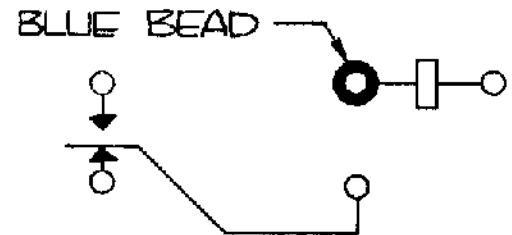

CONTACT RATING: 10 AMP/28 VDC  
RESISTIVE 50,000 OPERATIONS

DR. R.B. 1-14-91 | CK.1/14/91 JMB

 

**Communications  
Instruments, Inc.**

CUST. C.I.I. STD.  
 CUST. NO. \_\_\_\_\_

TYPE "C" RELAY

**CAW-1C-24B**