

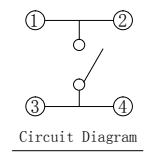
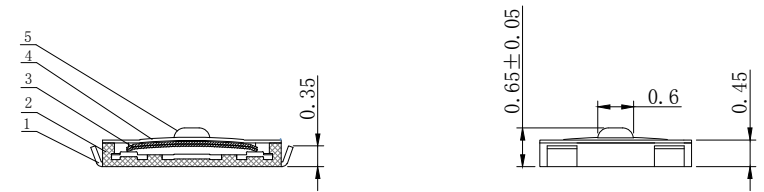
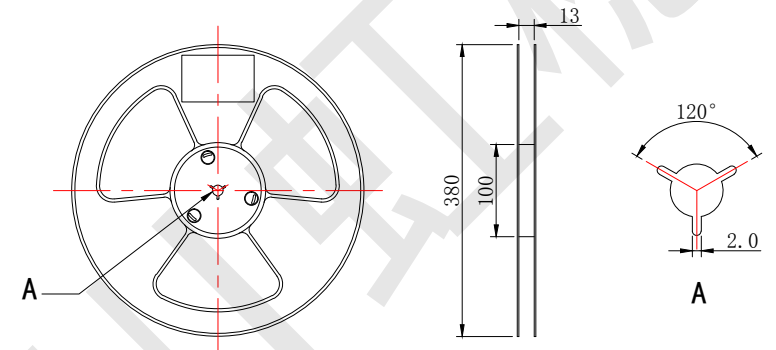
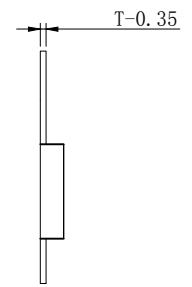
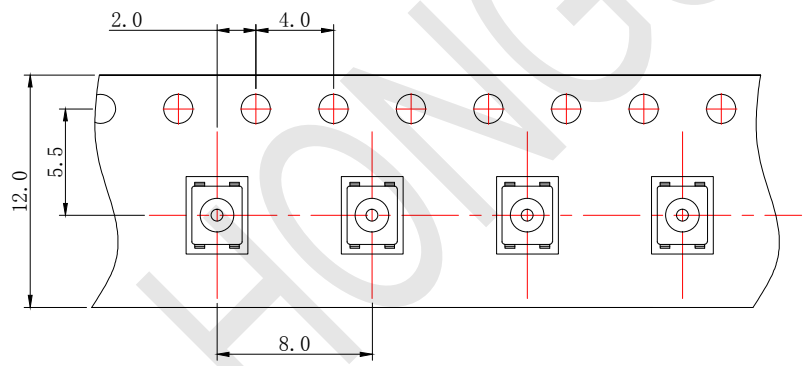
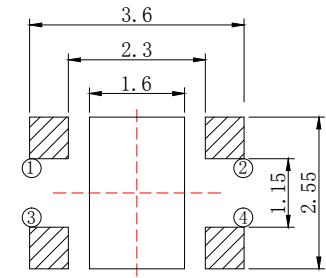


Version	Amendments	Modifier	Date Modified
A/0	新制定	杨国权	2019-2-21

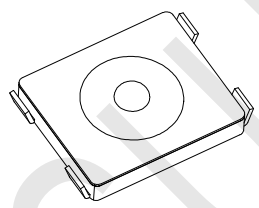

- Remarks:
1. Rated current, Voltage: DC 12V 50mA
  2. Contact resistance:  $\leq 100m\Omega$
  3. Insulation resistance:  $\geq 100M\Omega$
  4. The intensity of operations:  $200 \pm 50gf$
  5. Life requirements: 100000 times
  6. Withstand voltage: AC250V 1 minute
  7. All materials comply with RoHS standards

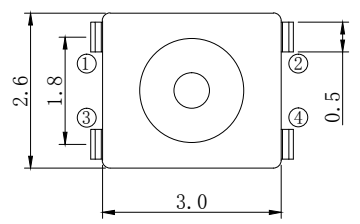

- Remarks:
- 1, The number of tapes per volume is 10000 PCS;
  - 2, Braiding process, can not be caused by carrying half crushed;
  - 3, Pay attention to the direction of the tape, with a clockwise direction out of the carrier tape, with a hole in the top or right

NO.	PART NAME	MATERIAL	QTY	FINISHING	General Tolerance	DRAWN	YANGBIAO	Product Name	Tact switch
5	Button	Polyimide	1	Black	$X \leq 1$	AFFIRM	YANGGUOQUAN	Model Number	TS26AB65A20B001
4	Paster	Polyimide	1	Yellow	$1 \leq X \leq 5$	AUDITING		DATE	2019-02-21
3	Shrapnel	SUS	2	Ag Plating	$5 \leq X \leq 10$				
2	Housing	LCP	1	Black	$X > 10$	SHEET	1:1 UNIT mm		
1	Terminal	Phosphor copper	4	Ag Plating	ANGLE				