


NO.1	
PART NO	H
A	4.3
C	5
G	7

NO.2	
PART NO	vigor
3	180±30
4	250±30

NO.3	
PART NO	MATERIAL/QTY
S	SUS/1PC
C	C5210/1PC
D	SUS/2PCS
F	C5210/2PCS

NO.4-NO.5	
PART NO	NOTE
01~99	SERIAL NUMBER

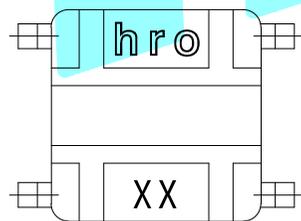

Typical Specifications

- 1.Rating : DC 12V 50mA
- 2.Contact Resistance: ≤100mΩ
- 3.Insulation Resistance: ≥100mΩ DC250V
- 4.Operating Temperature Range: -25°C+85°C
- 5.Ambient Humidity Used: ≤85%RH
- 6.Travel:0.25±0.1mm
- 7.Life : 100,000 Cycles
- 8.IP Rating: IP66

⑥	Cover	—	1	Brass	Tin Plated	—
⑤	Keystoke	—	1	Nylon	Red	—
④	Waterproof Silicone	—	1	Silica gel	Black	—
③	Contact	—	1	F.Ag/SUS	Plating silver	—
②	Base	—	1	Nylon	Black	—
①	Terminal	—	4	Copper(0.3t)	Plating silver	—
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK

APPROVALS			DATE		 ELECTRONICS CO.,LTD	
DRAWN	J.X.Zhang	2014/6/13				
CHECKED					TITLE: TACT SWITCHS	
APPROVALS					PART NO. K2-1110DP-□□□W-□□	
TOLERANCES ARE			30~以上	±0.30	ANGLE	UNIT: mm
			10~30	±0.20		
			5~10	±0.15		
			~ 5	±0.10		
			±2'	DRAWING NO.		SCALE: 1:1
			PROJ:		SHEET 1 OF 1	

ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.
	A		NEW			