

GT-TC034X-HXXXX-LX



G-SWITCH

Operating Force

A=160gf
B=250gf
C=100gf
D=350gf
G=130gf

Switch Height (mm)

H018=1.8mm
H025=2.5mm

Switch lifetime (Force)
L1=100,000 Cycles

 

G-Switch Specification:

Operating temperature range: -30°C to +85°C
Rating: 50mA, 12V DC
Insulation resistance: 100MΩ min, 100V DC
Dielectric strength: 250V AC for 1 min
Contact resistance: 100mΩ max.
Travel: 0.15±0.05mm



G-Switch Electronic (HongKong) CO., Ltd.

CIRCUIT DIAGRAM

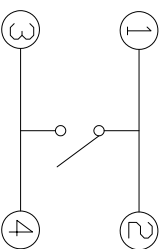

Unless otherwise specified, Tolerance:
±0.30
X ±0.20
X.X ±0.15
X.XXX ±0.10
Angles ±3

DESIGN	陈伟辉	DATE	2021.03.08
CHECKED		DATE	
APPROVED		DATE	
http://www.dg-switch.com			
TEL: 0769-82388879			

REV: X1	SCALE: 4:1	UNIT: mm
SIZE: A4	SHEET: 1/1	