

DC-044K-DXXX

DC Power jack


G-Switch P/N:

D: needle diameter
D020=2.0mm
D025=2.5mm

G-Switch Specification:
 Operating temperature range: -30°C to +85°C
 Rating: 7.0A, 24V DC
 Insulation resistance: 100MΩ min, 100V DC
 Dielectric strength: 500V AC for 1 min
 Contact resistance: 30mΩ max.
 Life: 5,000 Cycles



G-Switch Electronic (HongKong) CO., Ltd.

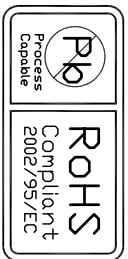

Unless otherwise specified, Tolerance:
 ±0.30
 X ±0.20
 X.X ±0.15
 X.XXX ±0.10
 Angles ±5

DESIGN	陈维彬	DATE	2016.05.29	TITLE:	DC-044K-DXXX
CHECKED		DATE		REV: X1	SCALE: 4:1
APPROVED		DATE		SIZE: A4	SHEET: 1/1
http://www.dg-switch.com				UNIT:	mm
TEL: 0769-82388879					

