

SK-24F01-GXXX

手柄


G-Switch P/N

Switch Height (mm)

| | |
|----------|-----------|
| G020=2.0 | G030=3.0 |
| G040=4.0 | G050=5.0 |
| G055=5.5 | G060=6.0 |
| G065=6.5 | G070=7.0 |
| G075=7.5 | G080=8.0 |
| G085=8.5 | G090=9.0 |
| G095=9.5 | G100=10.0 |

G-Switch Specification:

- Electrical Specifications: 1.0A/DC24V
- Contact resistance (CR): $\leq 50\text{m}\Omega$
- Insulation Resistance(IR): $\geq 100\text{M}\Omega$ DC250V
- Compressive strength (WV): AC250V 1minute
- Operating temperature: $-25^{\circ}\text{C}\sim+70^{\circ}\text{C}$
- Storage humidity: $<85\%\text{RH}$
- Electrical life: 10,000Cycles.

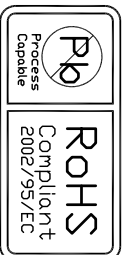

G-Switch Electronic (HongKong) CO.,Ltd.

Unless otherwise specified, Tolerance:
 X .30
 X .XX
 X .XX
 X .XXX
 Angles
 F3

| | | | | | |
|--------------------------|------------|------|------------|-------------|------------|
| DESIGN | Bright Lee | DATE | 2016.05.29 | MoIde code: | |
| CHECKED | | DATE | | | |
| APPROVED | | DATE | | | |
| http://www.dg-switch.com | | | | REV: X1 | SCALE: 4:1 |
| TEL:0769-82388879 | | | | SIZE: A4 | SHEET: 1/1 |
| | | | | UNIT: mm | |

SK-24F01-GXXX